


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

11.0" X 11.0" , 9.2" Focal Length, Fresnel

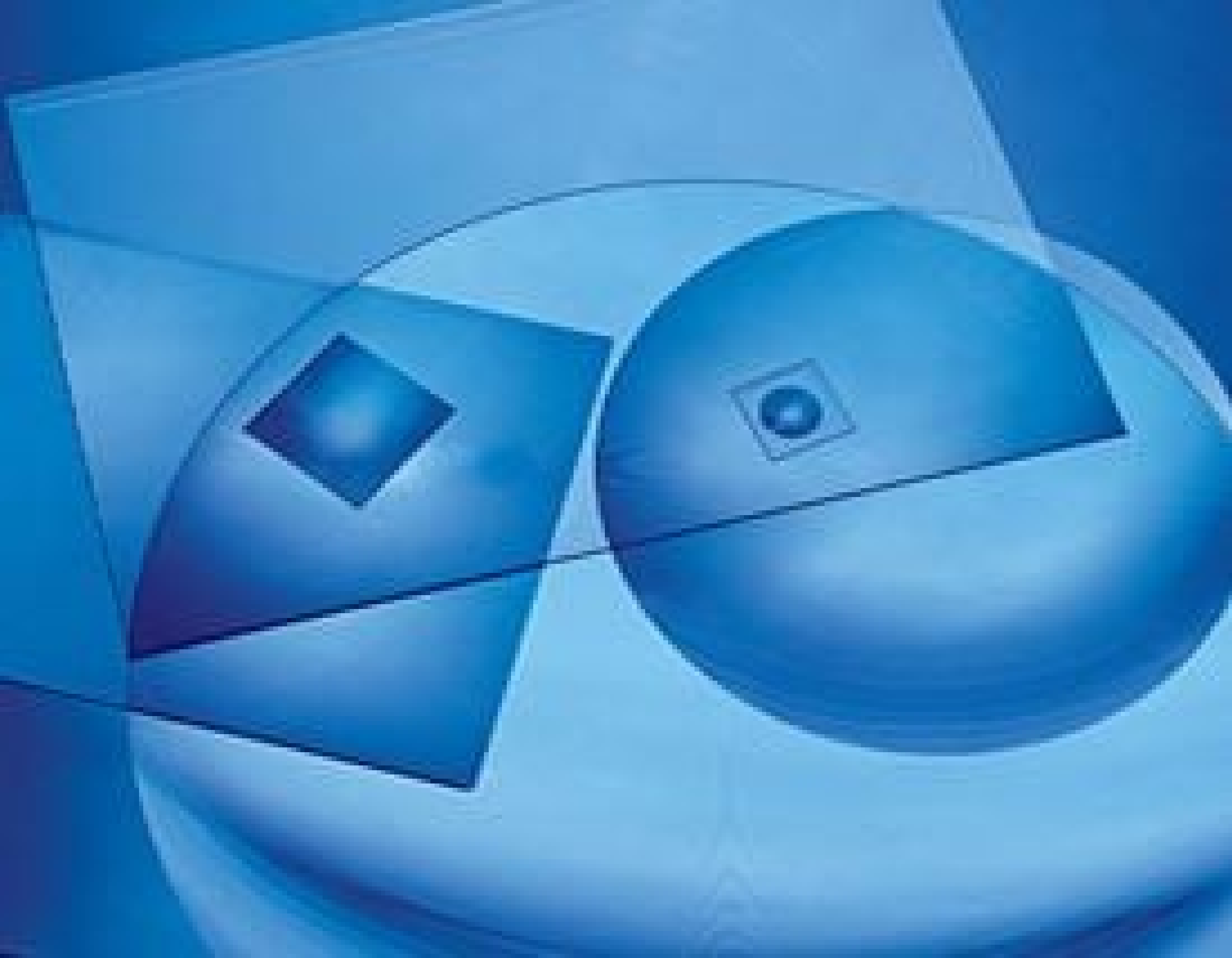

Aspherically Contoured Fresnel Lenses

Stock #32-598 ■ In Stock



1



€136,00

ADD TO CART

Qty 1-10

€136,00

Qty 11+

€119,00

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Effective Focal Length EFL (mm):
233.68

Substrate: ☐
Acrylic

Coating:
Uncoated

Type: Fresnel Lens
Wavelength Range (nm): 400 - 1100
Center Thickness CT (inches): 0.09
Dimensional Tolerance (inches): ±0.05
Dimensions (inches): 11.0 x 11.0
Dimensions (mm): 279.4 x 279.4
Effective Focal Length EFL (inches): 9.20
Effective Size (inches): 10.5 x 10.5
Groove Density (grooves/inch): 50.00
Index of Refraction n_d: 1.49
Operating Temperature (°C): 80 (Maximum)
Thickness Tolerance (%): ±40
Transmission (%): 85 (Typical)

Regulatory Compliance

RoHS 2015: Compliant
Reach 224: Compliant
Certificate of Conformance: View