


TECHSPEC® 125mm, Center Drive, Thru-Hole, Metric Micrometer Stage

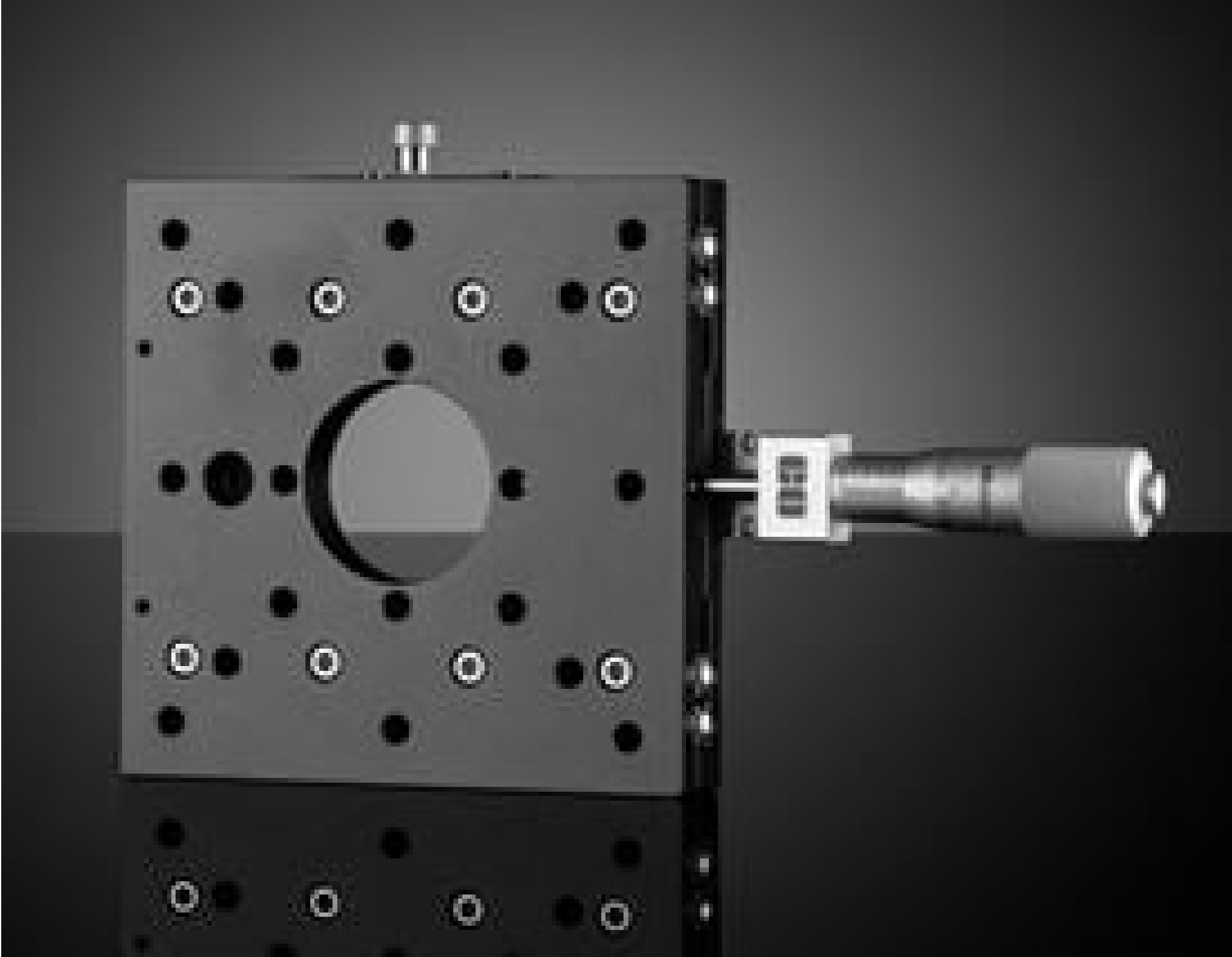

Stock **#66-469** 3-4 DAYS

⊖ 1 ⊕ **€620,00**

ADD TO CART

Qty 1-2
€620,00
Qty 3+
€543,40
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Type of Movement:
Linear (X)

Guide System:
Crossed Roller Bearing

Type of Drive:
Metric Micrometer

Drive Orientation:

Center Drive
Type: Metric
Stage Size (mm): 125 x 125
Travel (mm): 25
Center Hole: M42 x 0.75
Construction: Aluminium Stage
Leadscrew Pitch (mm): 0.5
Load Capacity (kg): 20
Mounting Threads: (1) M42 x 0.75, (20) M6 x 1
Stage Size (inches): 4.92 x 4.92
Straight Line Accuracy (µm): 2
Pitch (arcsec): 30
Yaw (arcsec): 25

Regulatory Compliance

RoHS 2015: Exempt
Certificate of Conformance: View
Reach 233: Contains SVHC(s)