


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

TECHSPEC® 12.5mm Dia. Laser Mirror Substrate

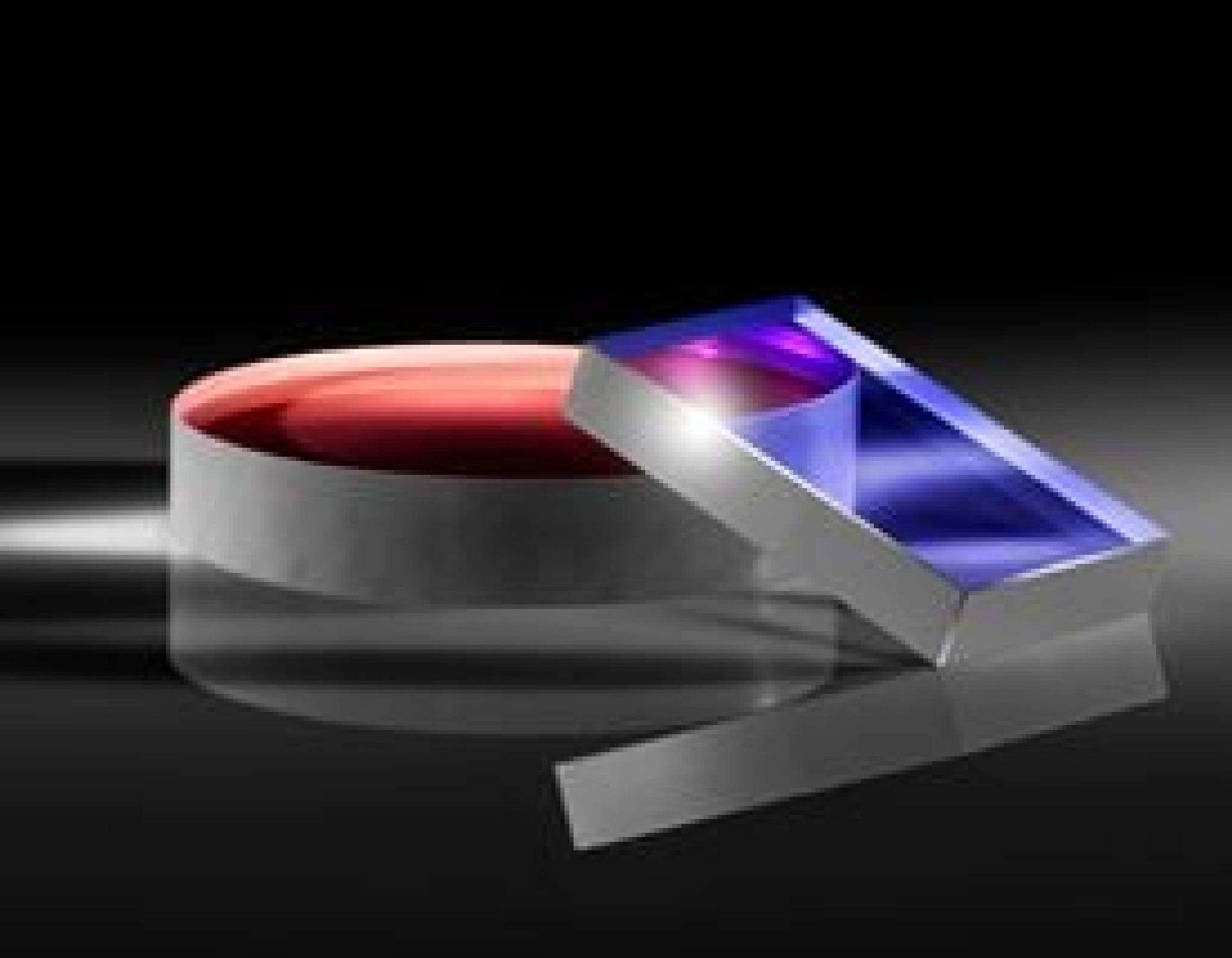

TECHSPEC® Laser Mirror Substrates

Stock #47-017 3-4 DAYS



1



€77,00

ADD TO CART

Qty 1-10

€77,00

Qty 11+

€67,00

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Surface Quality:
10-5

Type:
Laser Mirror Substrate

Parallelism (arcmin):
<3

Clear Aperture (%) : 90
Back Surface: Ground
Surface Flatness (P-V): λ/10
Coating: Uncoated
Diameter (mm): 12.50 +0.00/-0.20
Thickness (mm): 6.00 ±0.20
Substrate: Fused Silica (Corning 7980)

Regulatory Compliance

RoHS 2015: Compliant
Reach 197: Compliant
Certificate of Conformance: View