


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

TECHSPEC® 12.5mm Dia. X 25mm FL, Achromatic Cylinder Lens

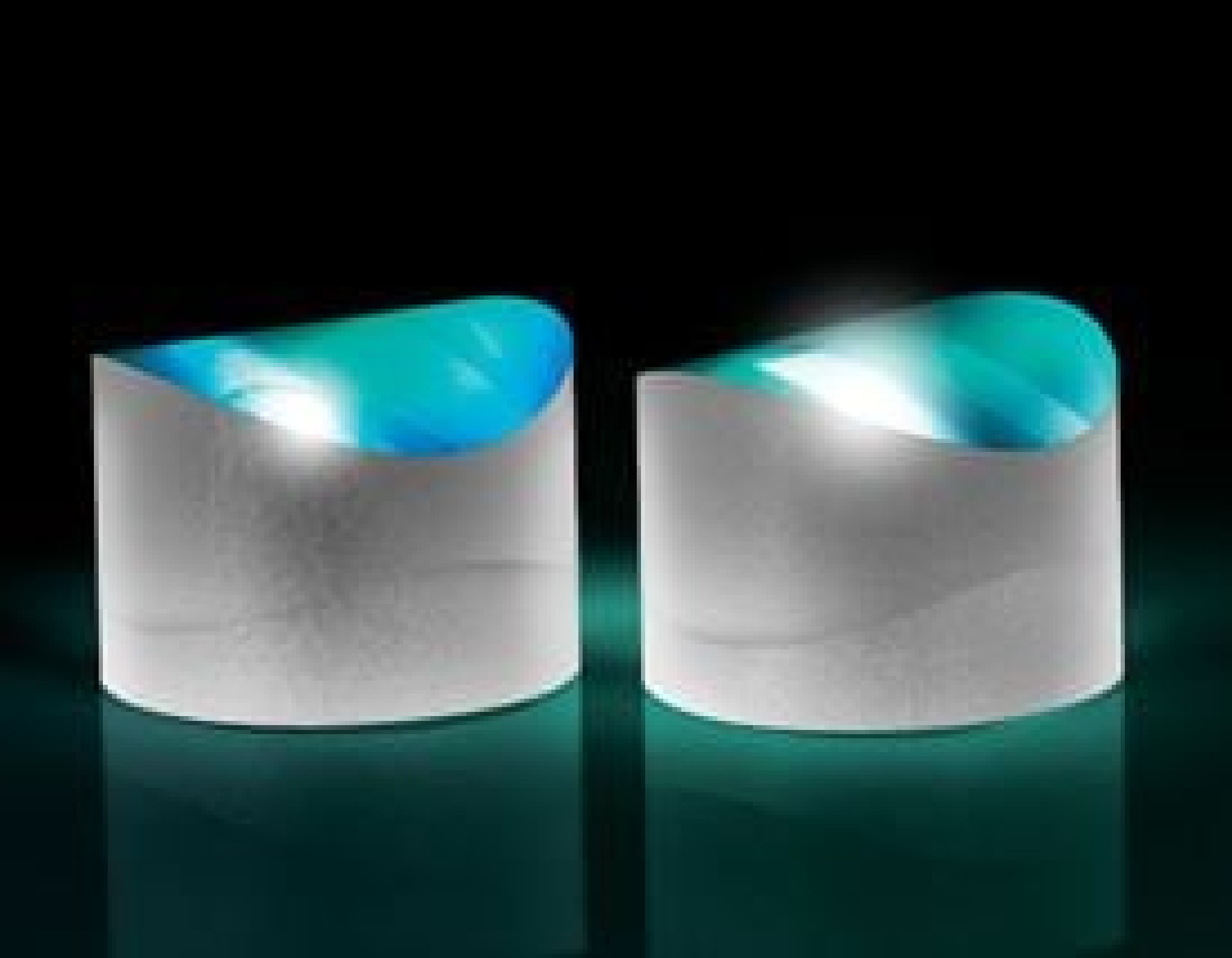

Stock #68-160 3-4 DAYS



1



€299,00

ADD TO CART

Qty 1+

€299,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
12.50 +0.0/-0.1

Effective Focal Length EFL (mm):
25.00

Substrate:
[N-BK7](#) / [N-SF5](#)

f/#:
2.00

Numerical Aperture NA:
0.25

Coating: MgF ₂ (400-700nm)
Type: Cylinder Lens, Achromatic
Wavelength Range (nm): 400 - 700
Back Focal Length BFL (mm): 18.23
Center Thickness Tolerance (mm): ±0.2
Coating Specification: R _{avg} ≤1.75% @400 - 700nm
Focal Length Tolerance (%): ±3
Radius R₁ (mm): 10.55
Radius R₂ (mm): -10.55
Radius R₃ (mm): -200.14
Surface Quality: 40-20
Center Thickness CT 1 (mm): 7.0
Center Thickness CT 2 (mm): 2.0

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View