


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

12.5" Diameter, 8.4" Focal Length, Fresnel Lens

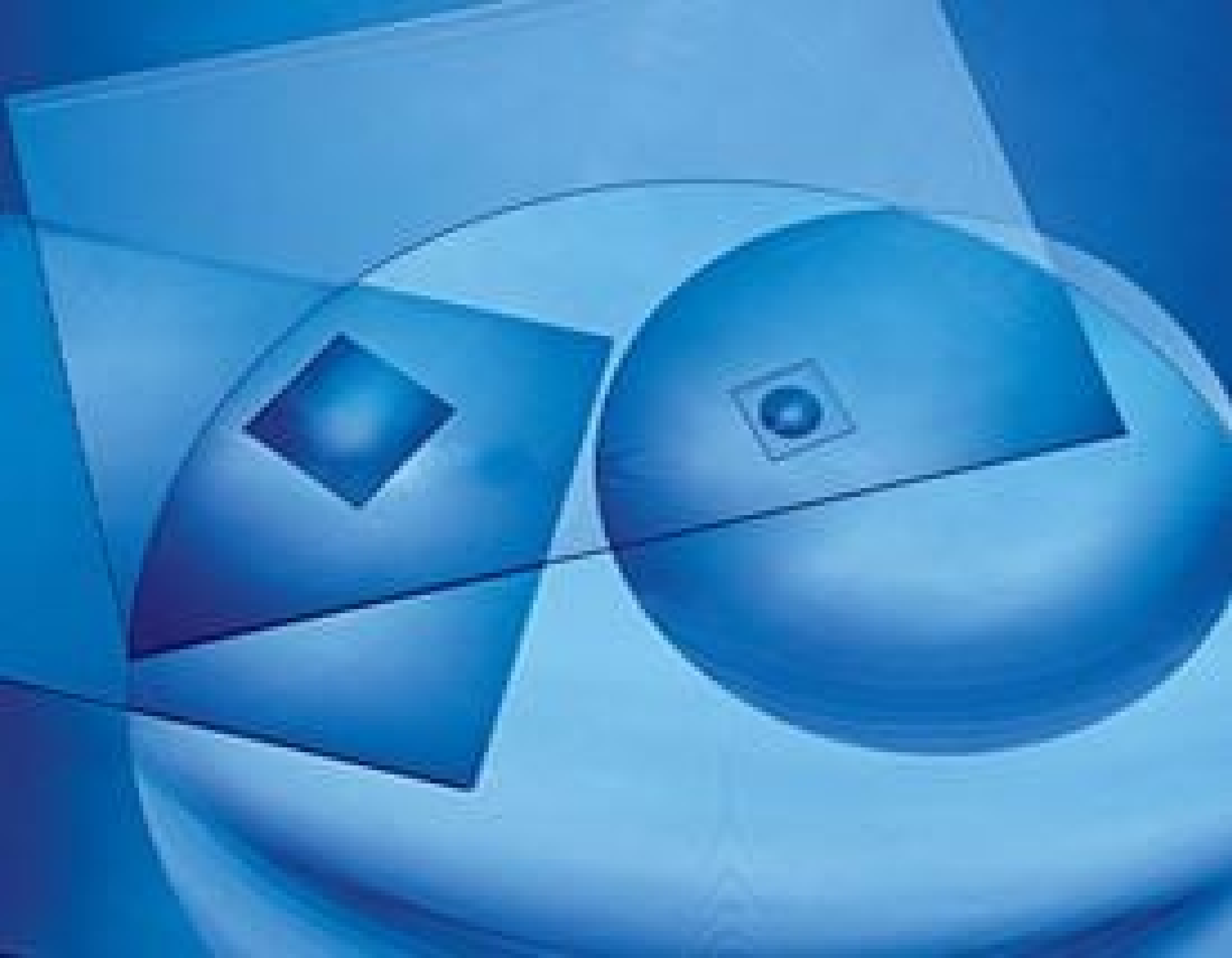

Aspherically Contoured Fresnel Lenses

Stock #46-391 3-4 DAYS



1



€224,00

ADD TO CART

Qty 1-10
€224,00

Qty 11+
€195,50

Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
317.50

Effective Focal Length EFL (mm):
213.36

Substrate: ☐
Acrylic

Coating: Uncoated
Type: Fresnel Lens
Wavelength Range (nm): 400 - 1100
Center Thickness CT (inches): 0.09
Diameter (inches): 12.5
Dimensional Tolerance (inches): ±0.05
Effective Diameter (inches): 12.0
Effective Focal Length EFL (inches): 8.40
Groove Density (grooves/inch): 50.00
Index of Refraction n_d: 1.49
Operating Temperature (°C): 80 (Maximum)
Thickness Tolerance (%): ±40
Transmission (%): 85 (Typical)

Regulatory Compliance

RoHS 2015: Compliant
Reach 224: Compliant
Certificate of Conformance: View