


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

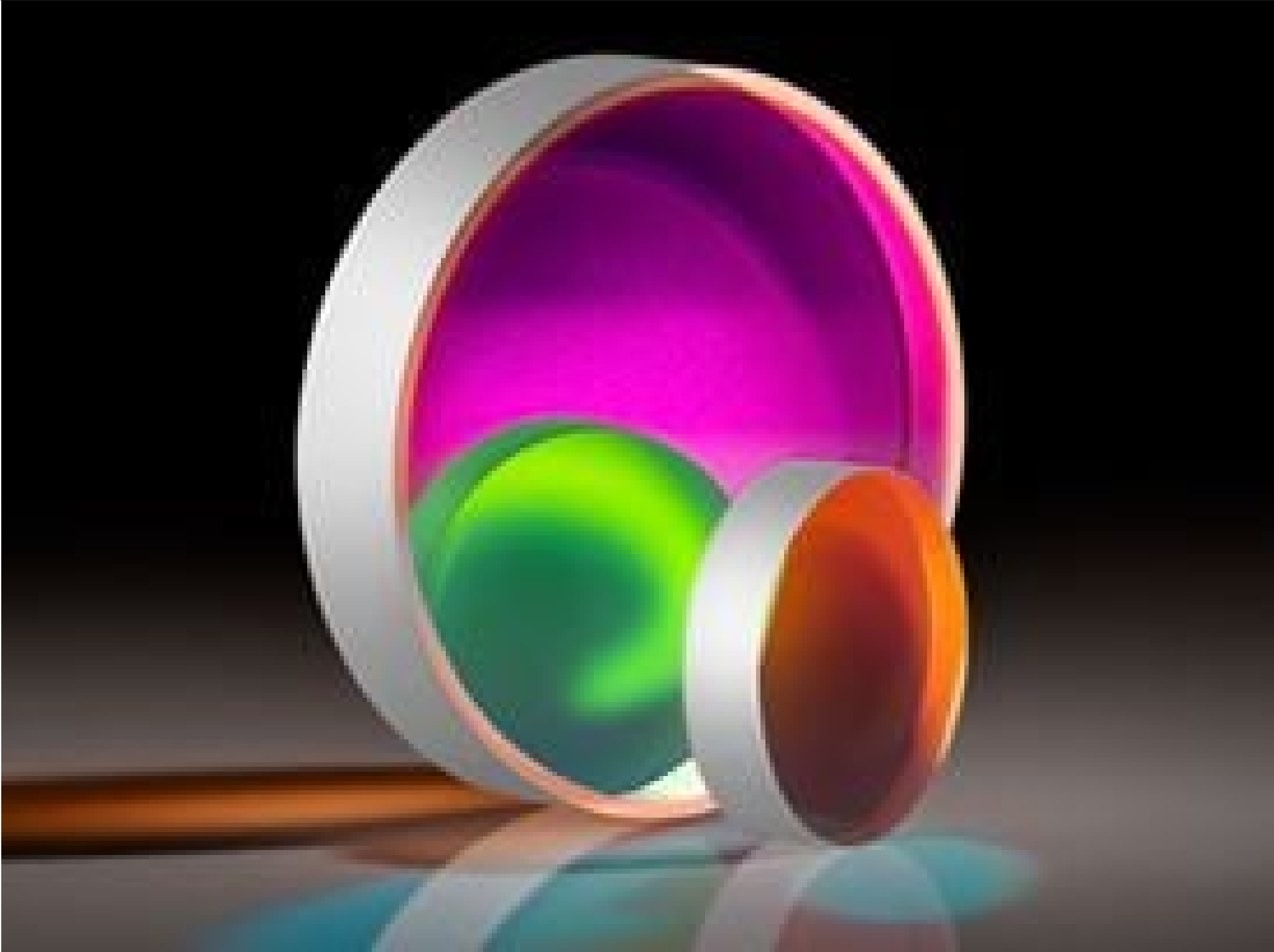

Stock #38-621 3-4 DAYS

1 €96,00

ADD TO CART

Qty 1-10

€96,00

Qty 11+

€87,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Quality:
20-10

Type:
Laser Mirror

Parallelism (arcmin):
<3

Clear Aperture (%) >90
Back Surface: Commercial Polish
Reflection at DWL (%) 99
Coating Specification: R_{abs} >99% @ 1064nm
Surface Flatness (P-V): λ/10
Coating Type: Dielectric
Coating: Laser Mirror (1064nm)
Design Wavelength DWL (nm): 1064
Diameter (mm): 12.70 +0.0/-0.1
Thickness (mm): 6.35 ±0.2
Angle of Incidence (°): 0
Substrate: N-BK7
Damage Threshold, By Design: 5 J/cm² @ 1064nm, 20ns, 20Hz

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View