


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

TECHSPEC® 12mm Dia. X -18mm FL, NIR I, Inked, Double-Concave Lens

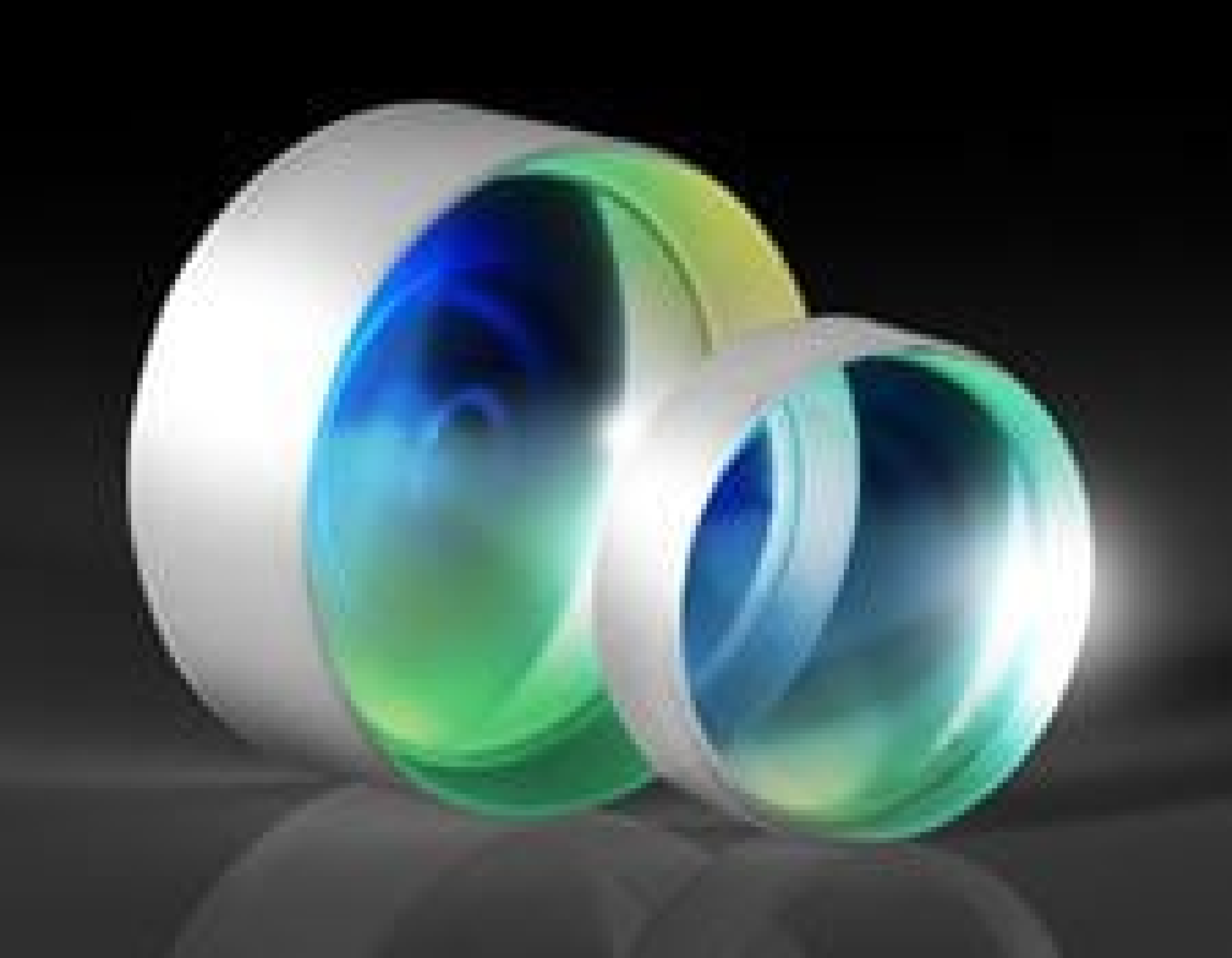

Stock #49-547-INK 3-5 DAYS

[Other Coating Options](#)



1



€51,50

ADD TO CART

Qty 1-9
€51,50

Qty 10+
€46,25

Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
12.00 ±0.025

Effective Focal Length EFL (mm):

-18.00
Substrate: N-BK7
f#: 1.5
Numerical Aperture NA: 0.33
Coating: NIR I (600-1050nm)
Type: Double-Concave Lens
Wavelength Range (nm): 600 - 1050
Back Focal Length BFL (mm): -18.65
Bevel: Protective bevel as needed
Center Thickness CT (mm): 2.00
Center Thickness Tolerance (mm): ±0.05
Centering (arcmin): <1
Clear Aperture CA (mm): 11.00
Coating Specification: Ravg ≤0.5% @ 600 - 1050nm
Edge Thickness ET (mm): 3.76
Focal Length Specification Wavelength (nm): 587.6
Focal Length Tolerance (%): ±1
Radius R₁=R₂ (mm): -18.94
Surface Quality: 40-20
Damage Threshold, By Design: 7 J/cm² @ 1064nm, 10ns
Power (P-V) @ 632.8nm: 1.5λ
Irregularity (P-V) @ 632.8nm: λ/4

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View