


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

TECHSPEC® 152.4mm Dia. N/10 ZEROBUR® Optical Flat

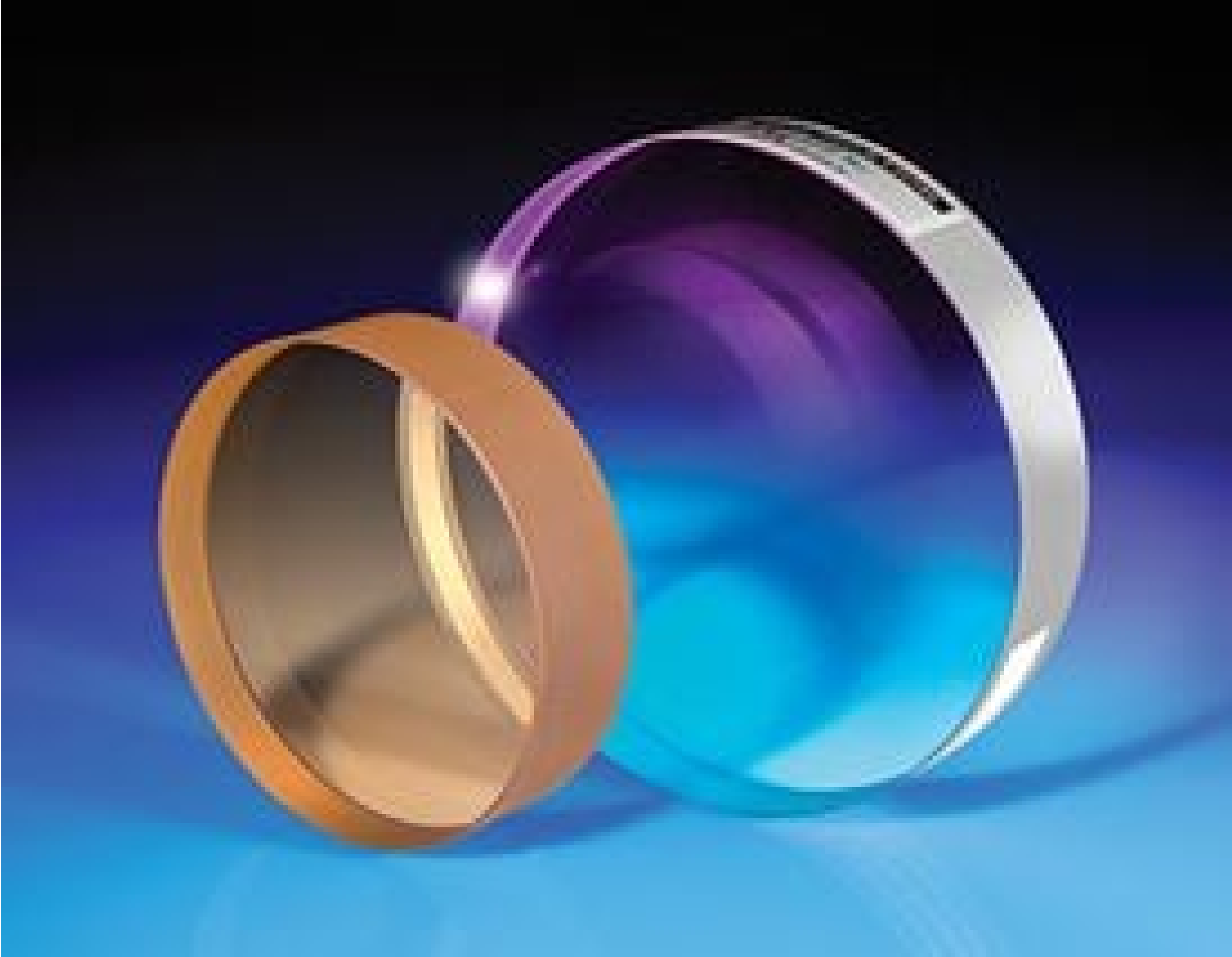

Stock #31-393-000 3-4 DAYS

1 €1.974,00

ADD TO CART

Qty 1-5

€1.974,00

Qty 6+

€1.777,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Surface Flatness (P-V):
N/10

Abbe Number (v_d):
56.2

Coating:

Uncoated
Coefficient of Thermal Expansion CTE (10⁻⁶/°C): 0.1
Diameter (mm): 152.40 +0.00/-1.00
Thickness (mm): 25.40 ±2.0
Diameter (inches): 6.00 +0.00/-0.04
Thickness (inches): 1.00 ±0.08
Clear Aperture CA (mm): 137.20
Color: Yellow Tint
Construction: Single Surface
Density (g/cm³): 2.53
Index of Refraction n_d: 1.542
Knoop Hardness (kg/mm²): 620
Parallelism (arcmin): ≤3
Poisson's Ratio: 0.24
Substrate: ZERODUR®
Surface Quality: 60-40
Type: Interferometry Window
Young's Modulus (GPa): 90.3
Bevel: Protective as needed

Regulatory Compliance

RoHS 2015: Compliant
Reach 211: Compliant
Certificate of Conformance: View