


In order to provide more accurate inventory information, please select your shipping country.

 
Select Your Country/Region: European Union



SUBMIT

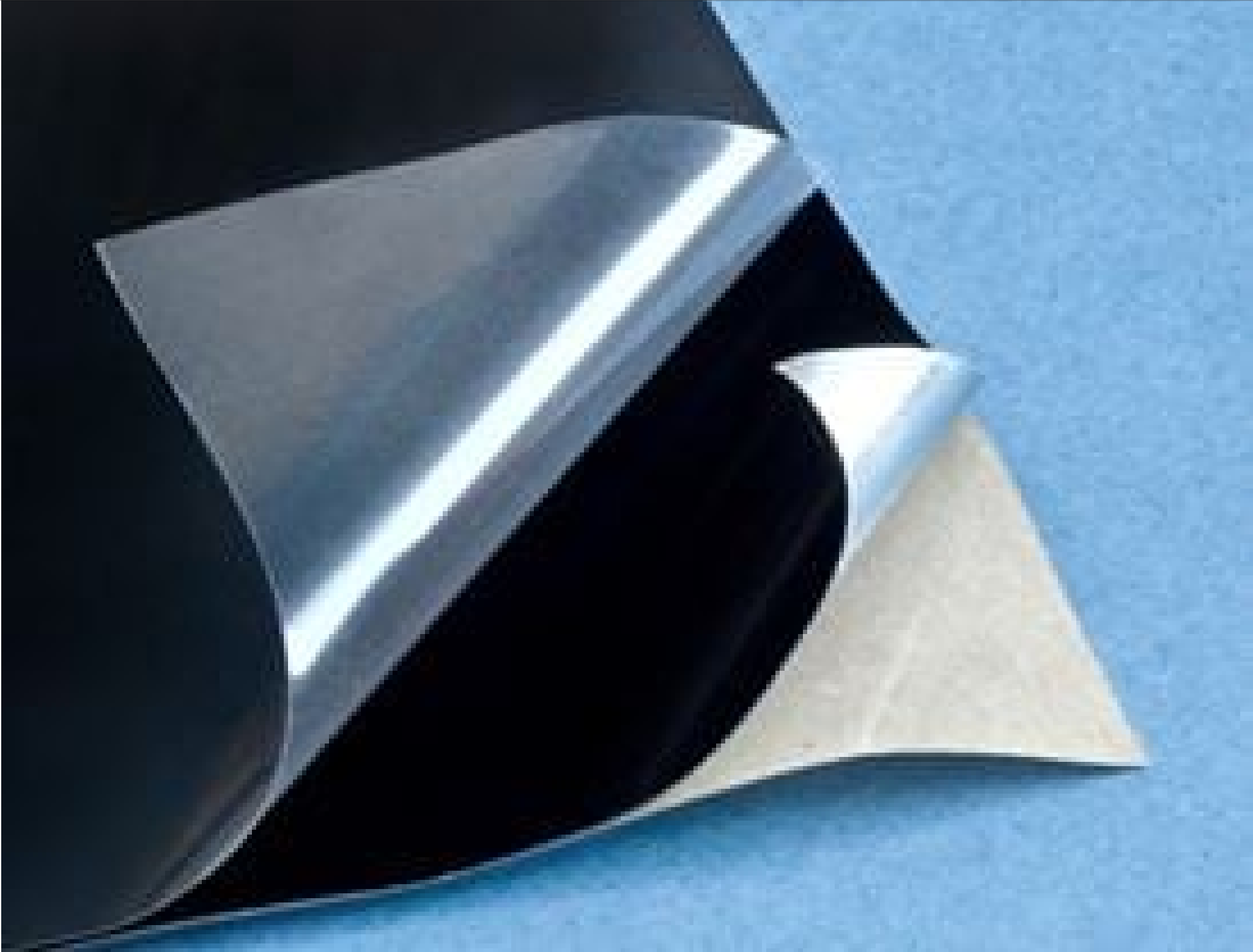

Acktar Light Absorbent Foil



Stock #20-064 3-4 DAYS



1



€117,50

ADD TO CART

Qty 1+

€117,50

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Coating:

MaxiBlack™

Model Number:

MXB-20X20-3

Operating Temperature (°C):

-40 to +150
Dimensions (mm): 200 x 200
Type: Low Outgassing Adhesive
Coating Thickness (µm): 4 - 6
Foil Thickness (µm): 75
Abrasion Resistance: Moderate
Adhesive Thickness (µm): 60
Humidity Resistance: ML-C-48497A
Wavelength Range (µm): 0.3 - 5
Dimensions (cm): 20 x 20
Note: Typical Adhesive Outgassing Performance: 0.85% TML, 0% VCM per ASTM E595-77/84/90

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 240: Compliant