


TECHSPEC® 203.2mm Dia. λ /20 ZERODUR® Optical Flat

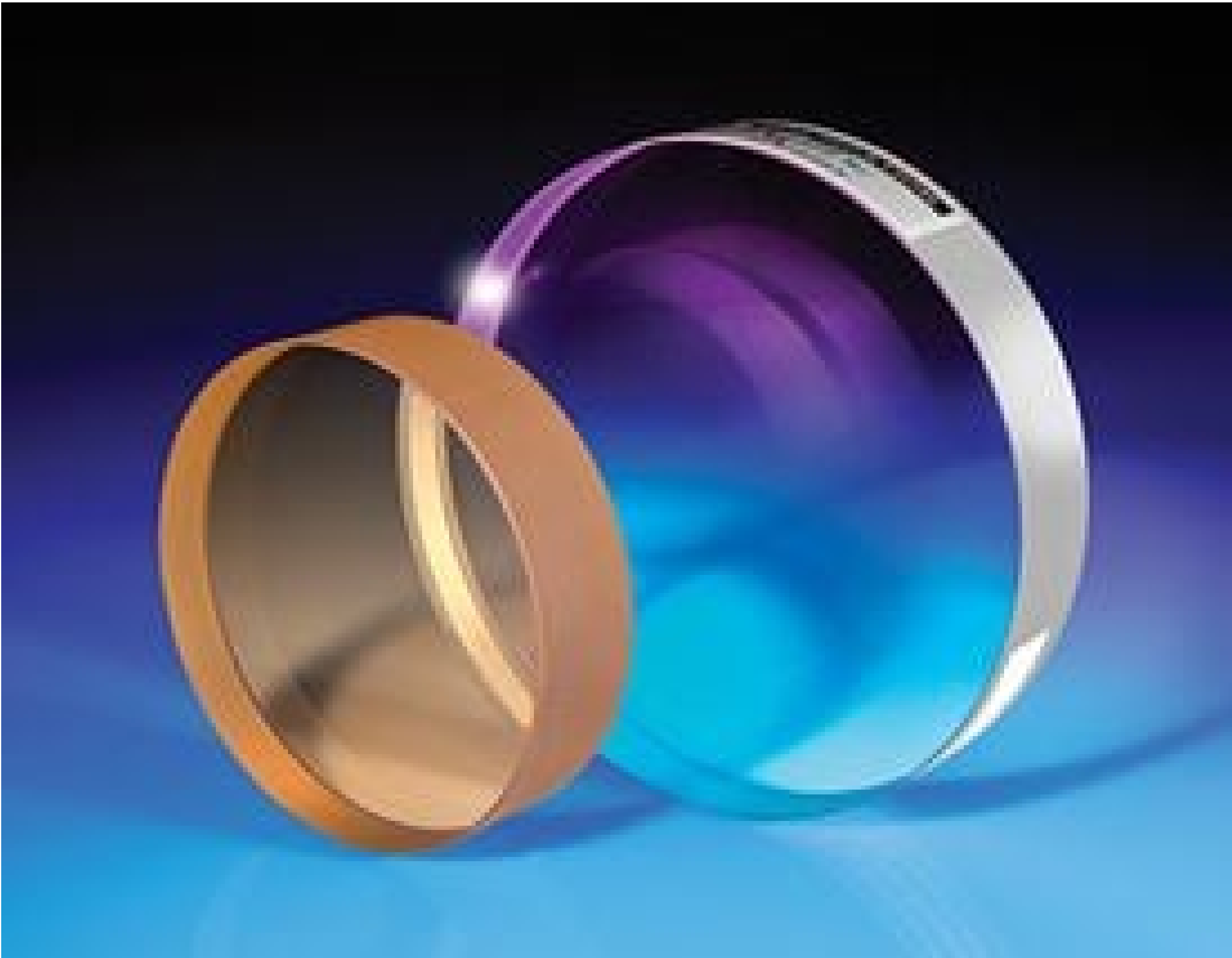

Stock **#49-049-000** 3-4 DAYS

- 1 + **€4.867,00**

ADD TO CART

Qty 1-2
€4.867,00
Qty 3+
€4.380,00
Volume Pricing
Request Quote

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Surface Flatness (P-V):
 λ /20

Abbe Number (v_d):
56.2

Coating:

Uncoated
Coefficient of Thermal Expansion CTE (10⁻⁶/°C): 0.1
Diameter (mm): 203.20 +0.00/-1.00
Thickness (mm): 38.10 ±2.5
Diameter (inches): 8.00 +0.00/-0.04
Thickness (inches): 1.50 ±0.10
Clear Aperture CA (mm): 182.90
Color: Yellow Tint
Construction: Single Surface
Density (g/cm³): 2.53
Index of Refraction n_d: 1.542
Knoop Hardness (kg/mm²): 620
Parallelism (arcmin): ≤3
Poisson's Ratio: 0.24
Substrate: ZERODUR®
Surface Quality: 60-40
Type: Interferometry Window
Young's Modulus (GPa): 90.3
Bevel: Protective as needed

Regulatory Compliance

RoHS 2015: Compliant
Reach 211: Compliant
Certificate of Conformance: View