


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

2.44" Diameter Linear-Rotary Positioning Stage

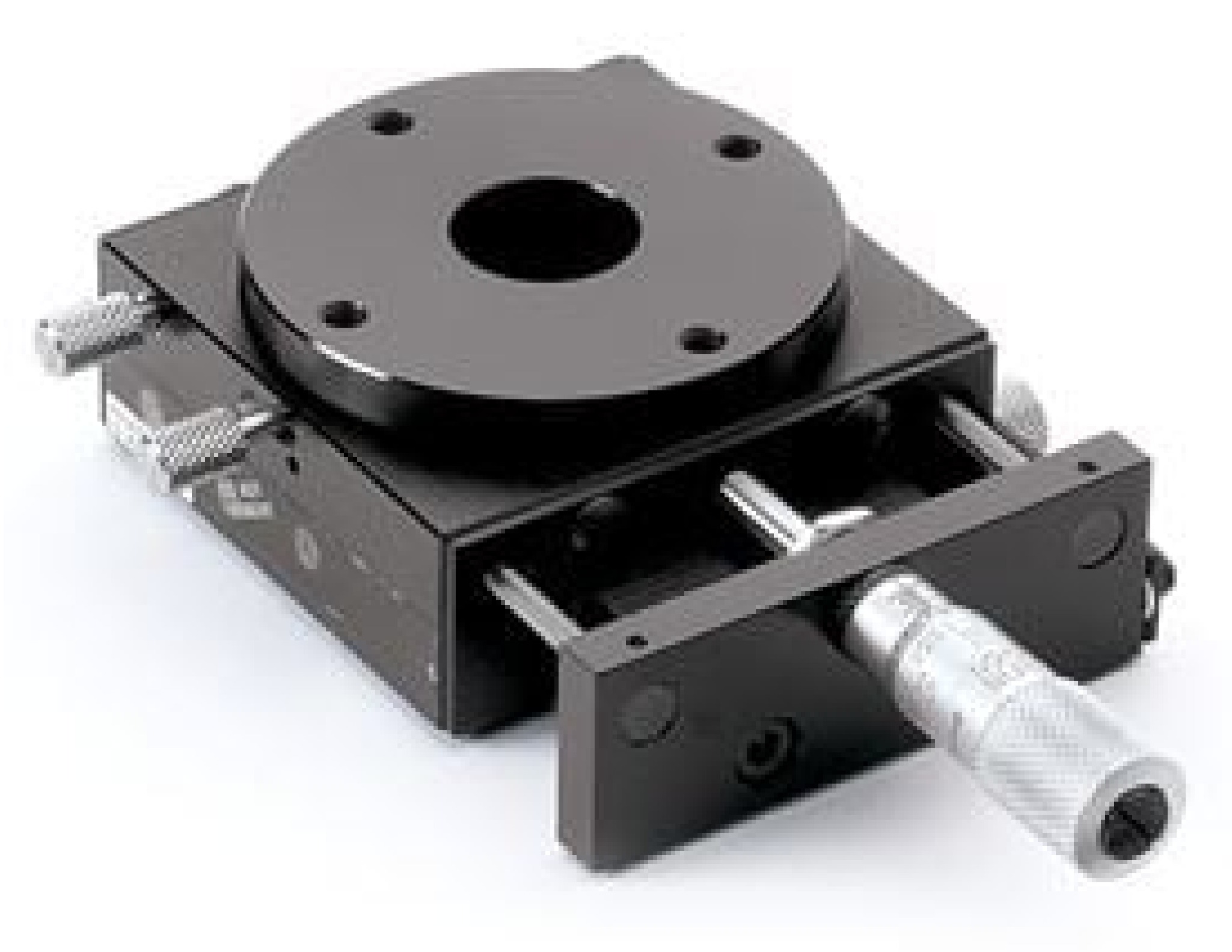

Linear-Rotary Positioning Stage, #38-198

Stock #38-198 [CONTACT US](#)



1



€976,00

ADD TO CART

Qty 1+

€976,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Type of Movement:
Linear (X) & Rotary

Type of Drive:
English Micrometer

Drive Orientation:
Center Drive

Type:
English

Stage Size (mm):

66.5 x 66.5
Travel (inches): 0.5
Travel (°): ±5 (Fine), 360 (Coarse)
Center Hole: 0.75" Dia. Thru
Construction: Aluminum Top and Base; Steel Tangent Arm Drive
Graduation (inches): 0.001
Load Capacity, Normal (lbs): 5
Mounting Threads: (4) 10-32 on 2" Dia. B.C.
Stage Size (inches): 2.62 x 2.62
Straight Line Accuracy (inches): 0.0001
Weight (lbs): 1

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View