


25,400 Lines/Inch, 6" x 12" Sheets, 2/Pack, Holographic Diffraction Grating Film

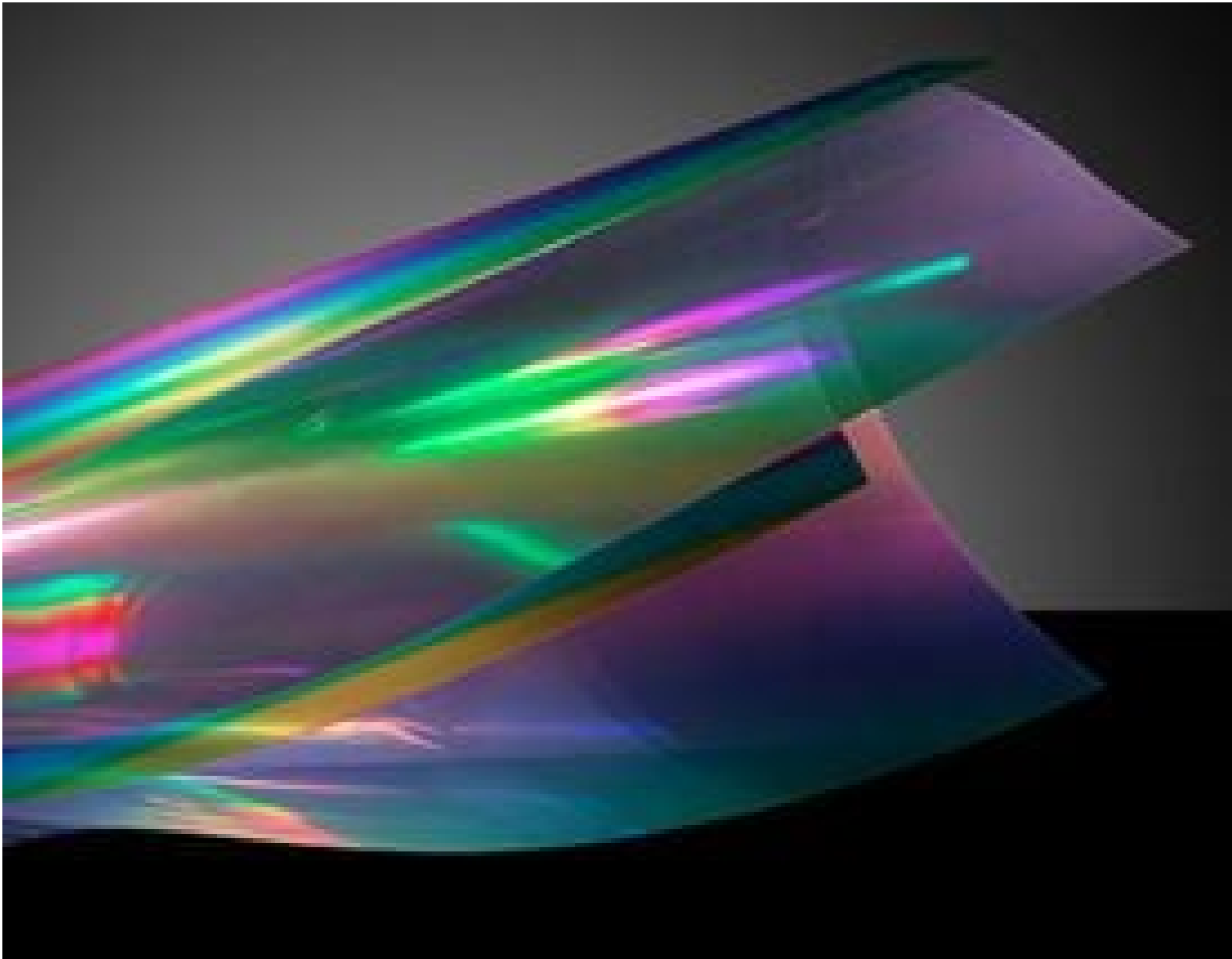

Holographic Diffraction Grating Film (Roll/Sheet)

Stock **#40-267** 3-4 DAYS

⊖ 1 ⊕ **€16,50**

ADD TO CART

Qty 1+

€16,50

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Groove Density (grooves/mm):
1000

Groove Density (grooves/inch):
25400

Wavelength Range (nm):
400 - 700

Dimensions (mm):
152.40 x 304.80

Dimensions (inches): 6 x 12
Construction: Holographic Grating
Dispersion Angle (°): 36
Length (mm): 304.80
Substrate: ☐ Clear Polyester Film
Thickness (inches): 0.003
Type: Transmission Diffraction Grating
Width (mm): 152.40
Quantity: 2 Sheets

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant