


TECHSPEC® 25.4mm Dia. λ /10 ZERODUR® Optical Flat

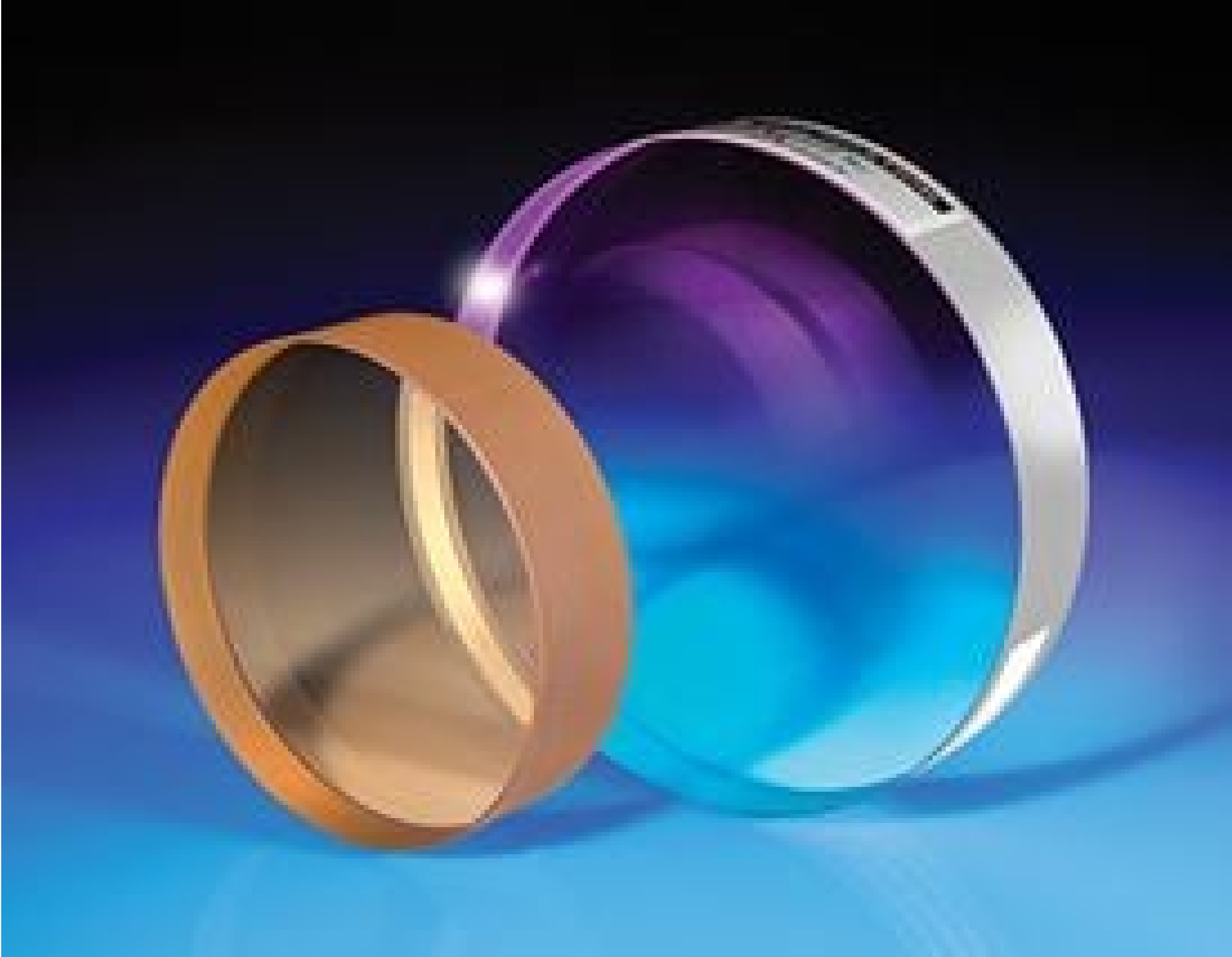

Stock **#32-195-000** [CONTACT US](#)



1



€142,00

ADD TO CART

Qty 1-10

€142,00

Qty 11+

€128,00

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Surface Flatness (P-V):
 λ /10

Abbe Number (v_d):
56.2

Coating:

Uncoated
Coefficient of Thermal Expansion CTE (10⁻⁶/°C): 0.1
Diameter (mm): 25.40 +0.00/-1.00
Thickness (mm): 12.70 ±1.5
Diameter (inches): 1.00 +0.00/-0.04
Thickness (inches): 0.50 ±0.06
Clear Aperture CA (mm): 22.90
Color: Yellow Tint
Construction: Single Surface
Density (g/cm³): 2.53
Index of Refraction n_d: 1.542
Knoop Hardness (kg/mm²): 620
Parallelism (arcmin): ≤3
Poisson's Ratio: 0.24
Substrate: ZERODUR®
Surface Quality: 60-40
Type: Interferometry Window
Young's Modulus (GPa): 90.3
Bevel: Protective as needed

Regulatory Compliance

RoHS 2015: Compliant
Reach 224: Compliant
Certificate of Conformance: View