


TECHSPEC® 25.4mm Dia. VIS, Precision Broadband Laser Mirror

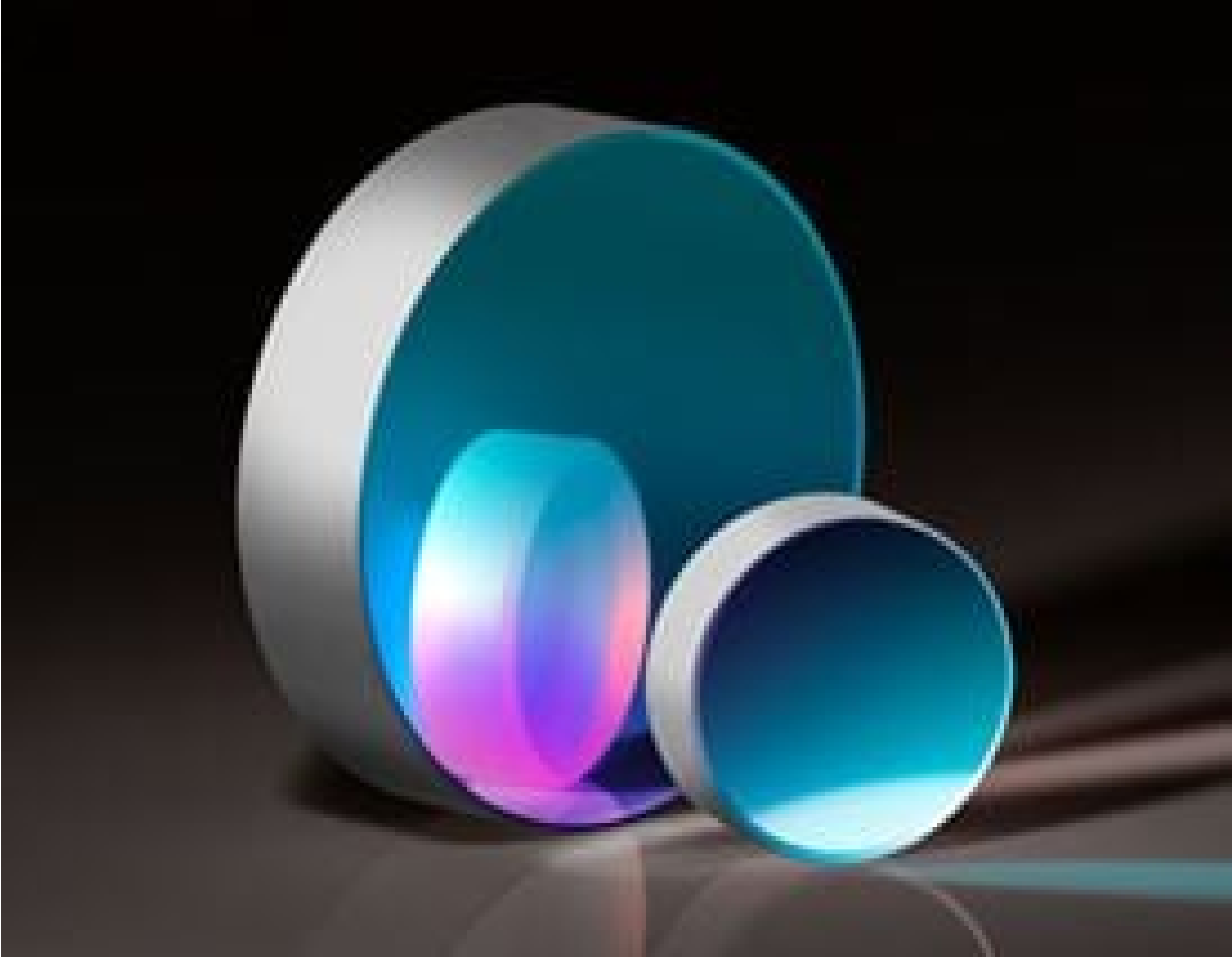

Stock **#45-596** ☐ In Stock

1 **€156,00**

ADD TO CART

Qty 1-5
€156,00

Qty 6+
€137,00

Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Quality:
20-10

Type:
Laser Mirror

Clear Aperture (%):
>80

Durability: ML-M-13508-C
Back Surface: Ground
Coating Specification: R_{avg} >99% @ 400 - 700nm
Wavelength Range (nm): 400 - 700
Surface Flatness (P-V): λ/10
Irregularity (P-V) @ 632.8nm: λ/20
Coating Type: Dielectric
Coating: Dielectric Mirror (400-700nm)
Diameter (mm): 25.40 +0.0/-0.2
Thickness (mm): 8.00 ±0.3
Angle of Incidence (°): 0-45
Substrate:  BOROFLOAT®
Note: Optical Power: λ/10
Damage Threshold, By Design:  1 J/cm² @ 10ns

Regulatory Compliance

RoHS 2015: Compliant
REACH 201: Compliant
Certificate of Conformance: View