


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

25.4mm Dia. X 3mm High Efficiency window

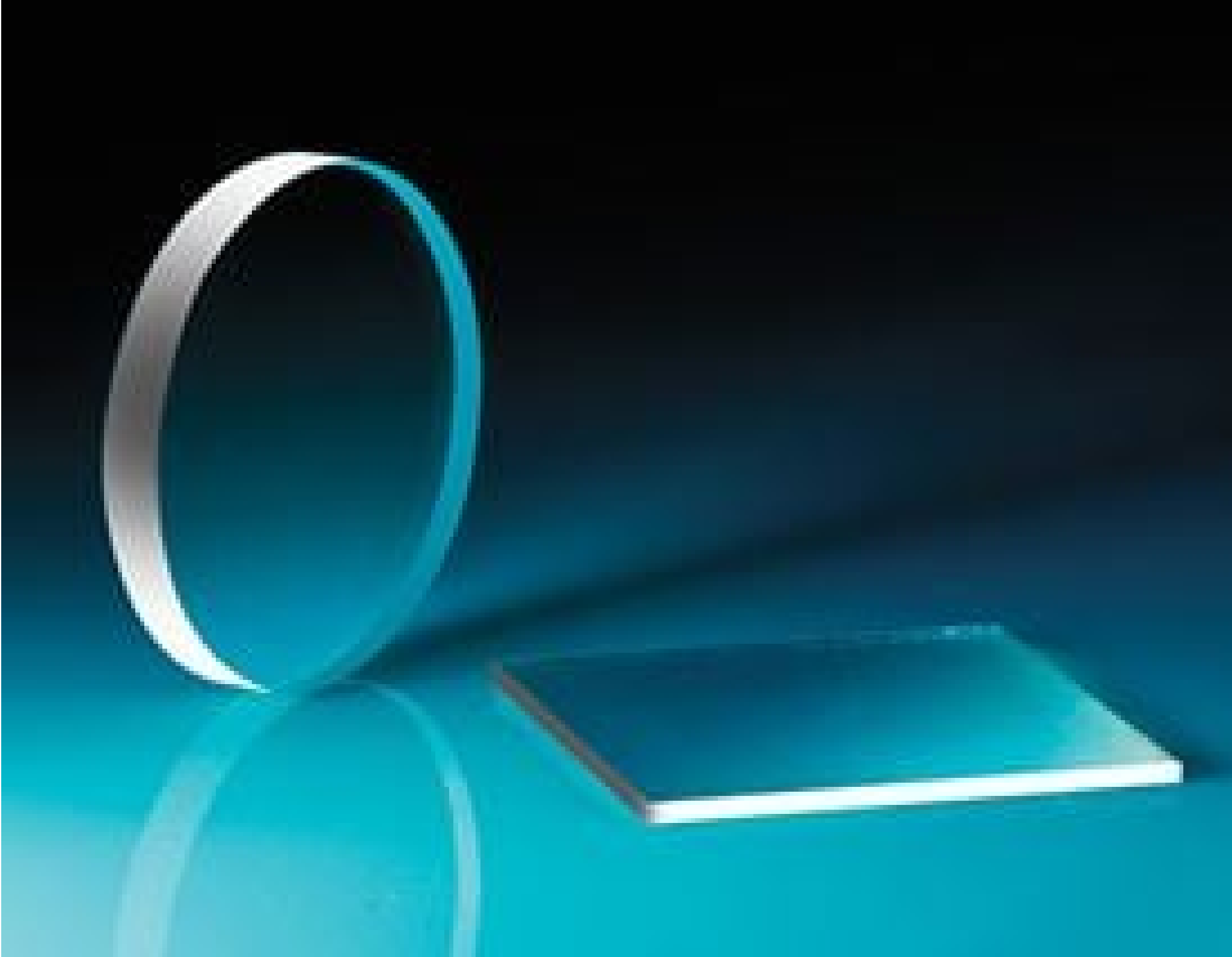

Stock #46-098 ☐ In Stock



1



€21,50

ADD TO CART

Qty 1-5

€21,50

Qty 6+

€17,25

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Angle of Incidence (°):
0

Bevel:
Protective as needed

Clear Aperture (%):
≥90

Clear Aperture CA (mm): 22.86
Diameter (mm): 25.40 ±0.76
Thickness (mm): 3.00 ±0.25
Coating: BBAR (425-700nm)
Coating Specification: R _{avg} ≤0.5% @ 425 - 700nm
Edges: Ground
Substrate: Float Glass
Surface Quality: 80-50
Transmission (%): 95.6 Average (typical)
Type: Protective Window
Wavelength Range (nm): 425 - 700

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View