


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

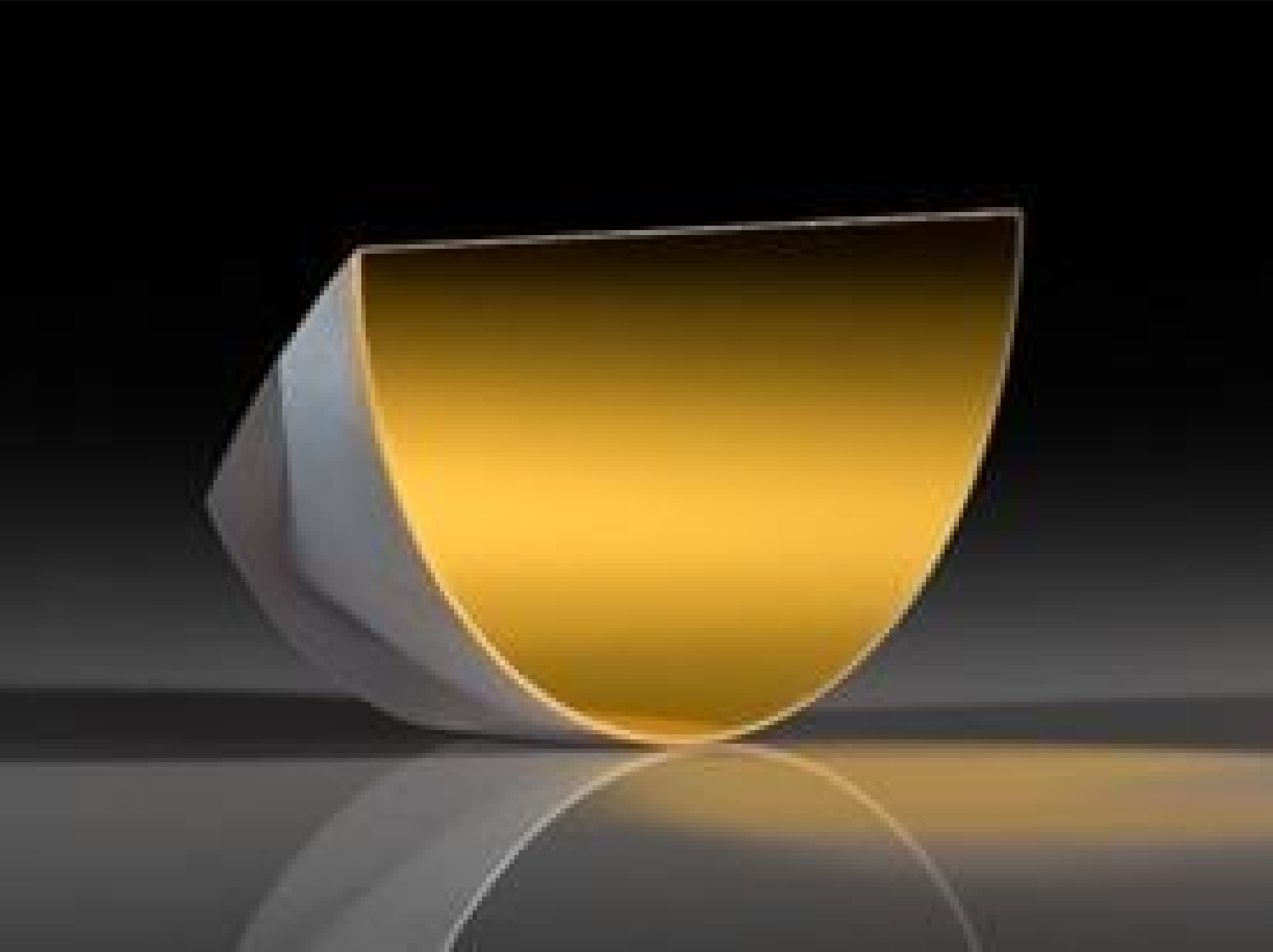

25.4mm Enhanced Protected Gold λ /10 D-Shaped Pickoff Mirror, #36-136

Stock #36-136 3-4 DAYS



1



€100,00

ADD TO CART

Qty 1-5

€100,00

Qty 6+

€90,00

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):

25.40

Surface Flatness (P-V):

λ /10

Substrate:

[Fused Silica](#) (Corning 7980)

Back Surface: Fine Grind
Surface Quality: 20-10
Dimensional Tolerance (mm): +0.0/-0.20
Coating Specification: R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm
Coating: Protected Gold (700-10000nm)
Coating Type: Metal
Bevel: Protective bevel as needed
Edges: Ground
Parallelism (arcmin): 2
Thickness (mm): 6.35
Thickness Tolerance (mm): ±0.20
Type: Flat Mirror
Wavelength Range (nm): 700 - 10000
Damage Threshold, Reference: ☐ 0.8 J/cm ² @ 1064nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant