


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

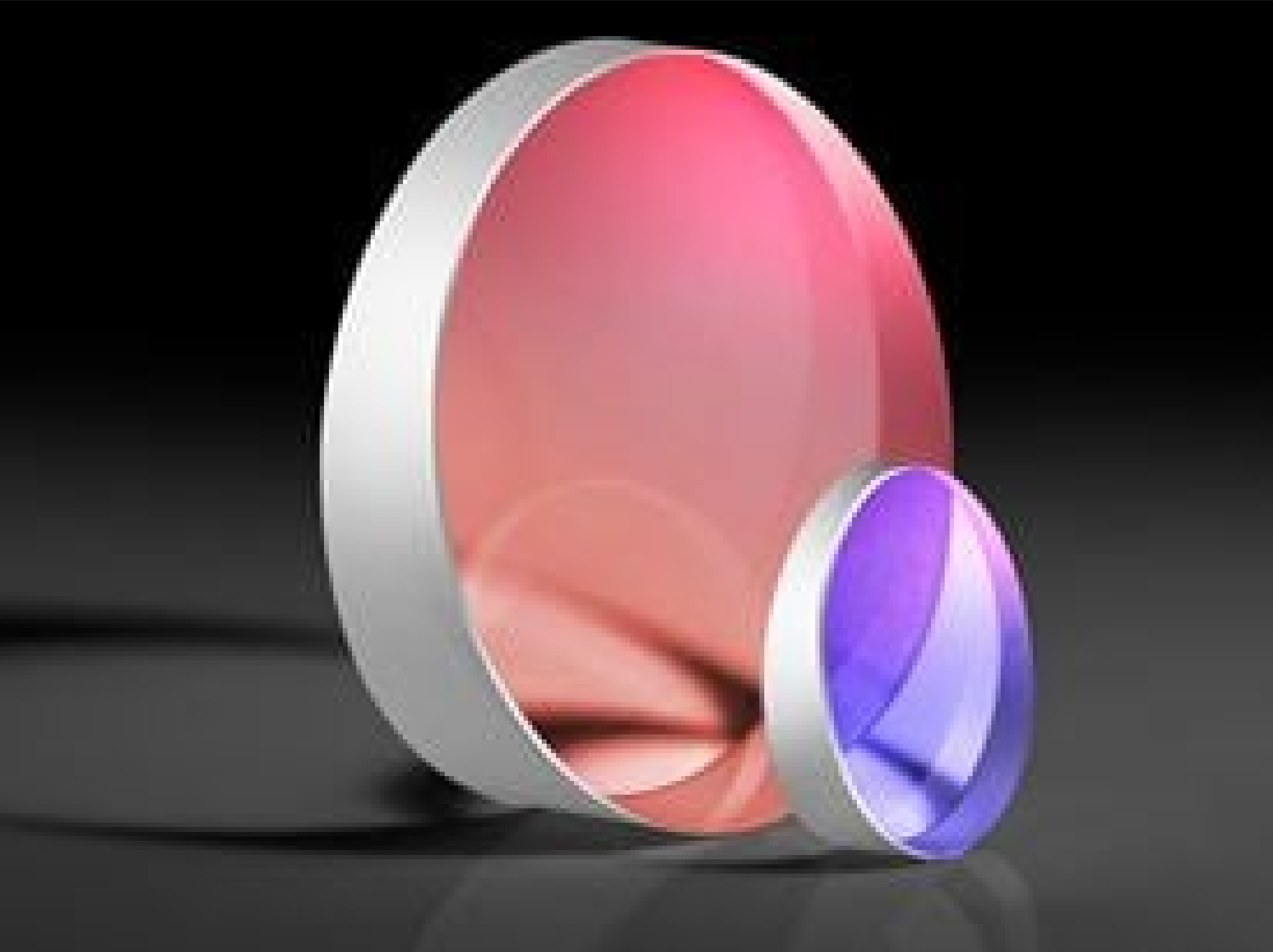

TECHSPEC Fused Silica Wedge Prisms

Stock #39-130 3-4 DAYS



1



€155,00

ADD TO CART

Qty 1-5

€155,00

Qty 6+

€124,00

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Coating:

Laser V-Coat (1064nm)

Angle Tolerance (arcsec):

15

Bevel:

Protective bevel as needed

Coating Specification: Rabs <0.25% @ 1064nm
Coefficient of Thermal Expansion CTE (10⁻⁶/°C): 0.52
Design Wavelength DWL (nm): 1064
Diameter (mm): 25.00
Image Orientation: Beam Deviation
Power (diopters): 0.87
Ray Deviation @ 355nm (°): 0.50
Substrate: Fused Silica (Coming 7980)
Surface Flatness (P-V): λ/10
Surface Quality: 20-10
Thickness (mm): 3.00
Wedge Angle: 1° 3'0"
Damage Threshold, By Design: 15 J/cm² @ 1064nm, 20ns, 20Hz

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View