


25mm Dia. Hexa-Black™ Panel

See More by [Acktar](#)

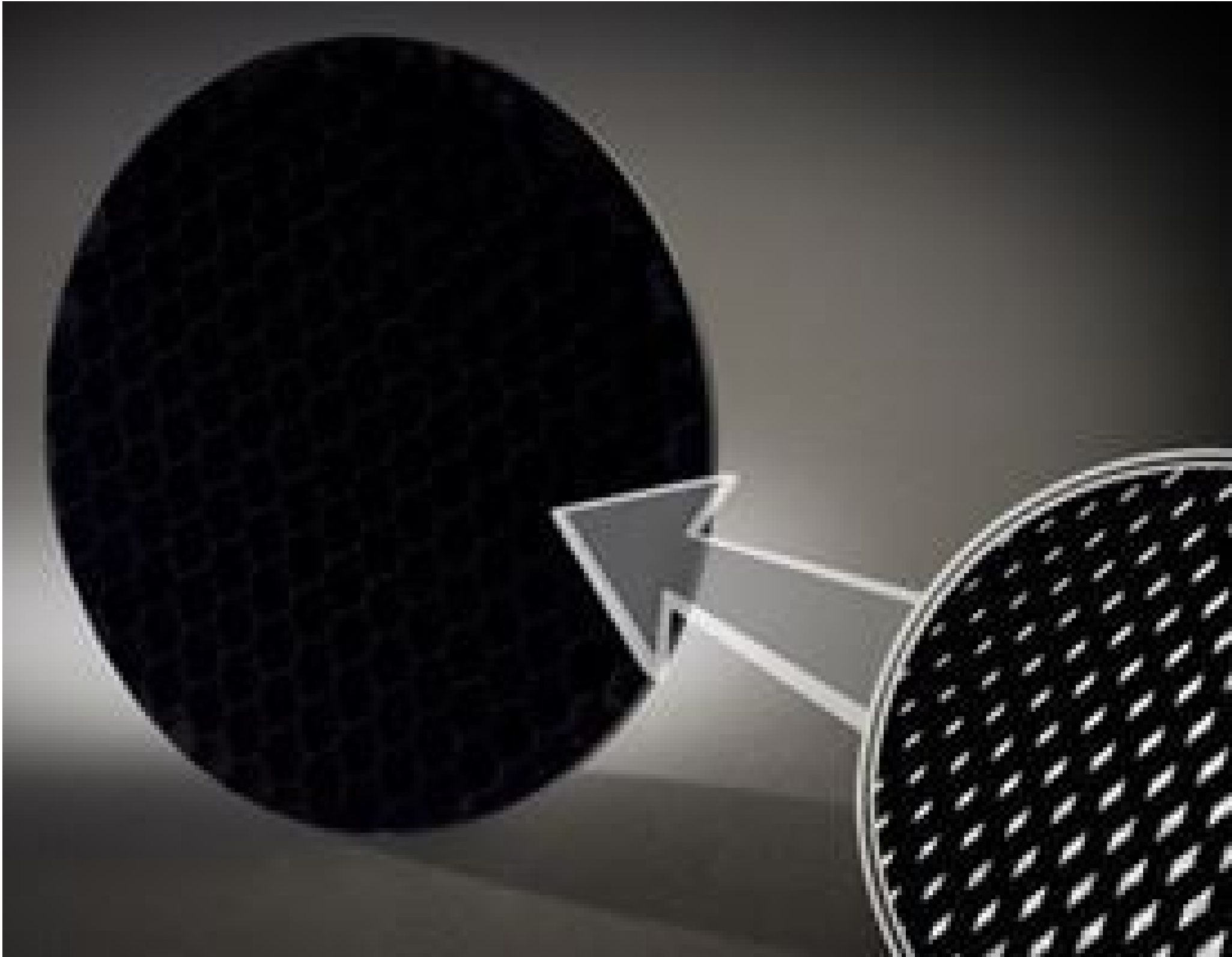

Acktar Hexa-Black™ Panel



Stock **#37-830** ☐ In Stock



1



€165,00

ADD TO CART

Qty 1+

€165,00

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Coating:
Vacuum Black™

Diameter (mm):
25.00

Model Number:

HBP-25-3
Operating Temperature (°C): -50 to 150
Abrasion Resistance: High
Absorbance (%): 99.9
Adhesive Thickness (µm): 60
Humidity Resistance: ML-C-48497A
Wavelength Range (µm): 0.3 - 5
Note: Ships with a low outgassing adhesive sticker that can be applied to the back surface
Thickness (mm): 3.00
Absorbance (AOI > 60) (%): 99.995

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 240: Compliant