

[See all 6 Products in Family](#)

25mm Dia. x 200mm FL Uncoated, DCX N-K5 Lens



Stock #32-902 CLEARANCE **20+ In Stock**

⊖ 1 ⊕ €23^{.75}

ADD TO CART

Volume Pricing

Qty 1+	€23,75 each
Need More?	Request Quote

! Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Double-Convex Lens **Type:**

Physical & Mechanical Properties

25.00 +0.00/-0.10 **Diameter (mm):**

<1 **Centering (arcmin):**

5.00 ±0.10 **Center Thickness CT (mm):**

4.25 **Edge Thickness ET (mm):**

24 **Clear Aperture CA (mm):**

Protective as needed **Bevel:**

Optical Properties

200.00 @ 587.6nm **Effective Focal Length EFL (mm):**

198.35 **Back Focal Length BFL (mm):**

Uncoated **Coating:**

N-K5 **Substrate:**

40-20 **Surface Quality:**

1.5λ **Power (P-V) @ 632.8nm:**

λ/4 **Irregularity (P-V) @ 632.8nm:**

±1 **Focal Length Tolerance (%):**

8.00 **f#:**

0.06 **Numerical Aperture NA:**

330 - 2500 **Wavelength Range (nm):**

Regulatory Compliance


[View](#) **Certificate of Conformance:**

Product Details

- N-K5 Substrate
- Various Anti-Reflection (AR) Coatings
- PCX and DCX Options Available

N-K5 Lenses are available in various diameters, focal lengths, as well as Plano-Convex and Double-Convex form factors. Anti-reflective coatings covering the VIS to NIR make these ideal for multiple applications.

Technical Information

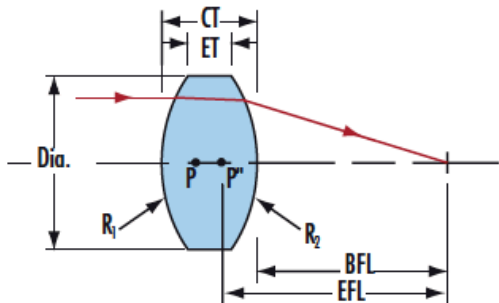

Compatible Mounts