


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

TECHSPEC® 25mm Dia X 20mm FL Acylinder Lens, MgF₂ Coated

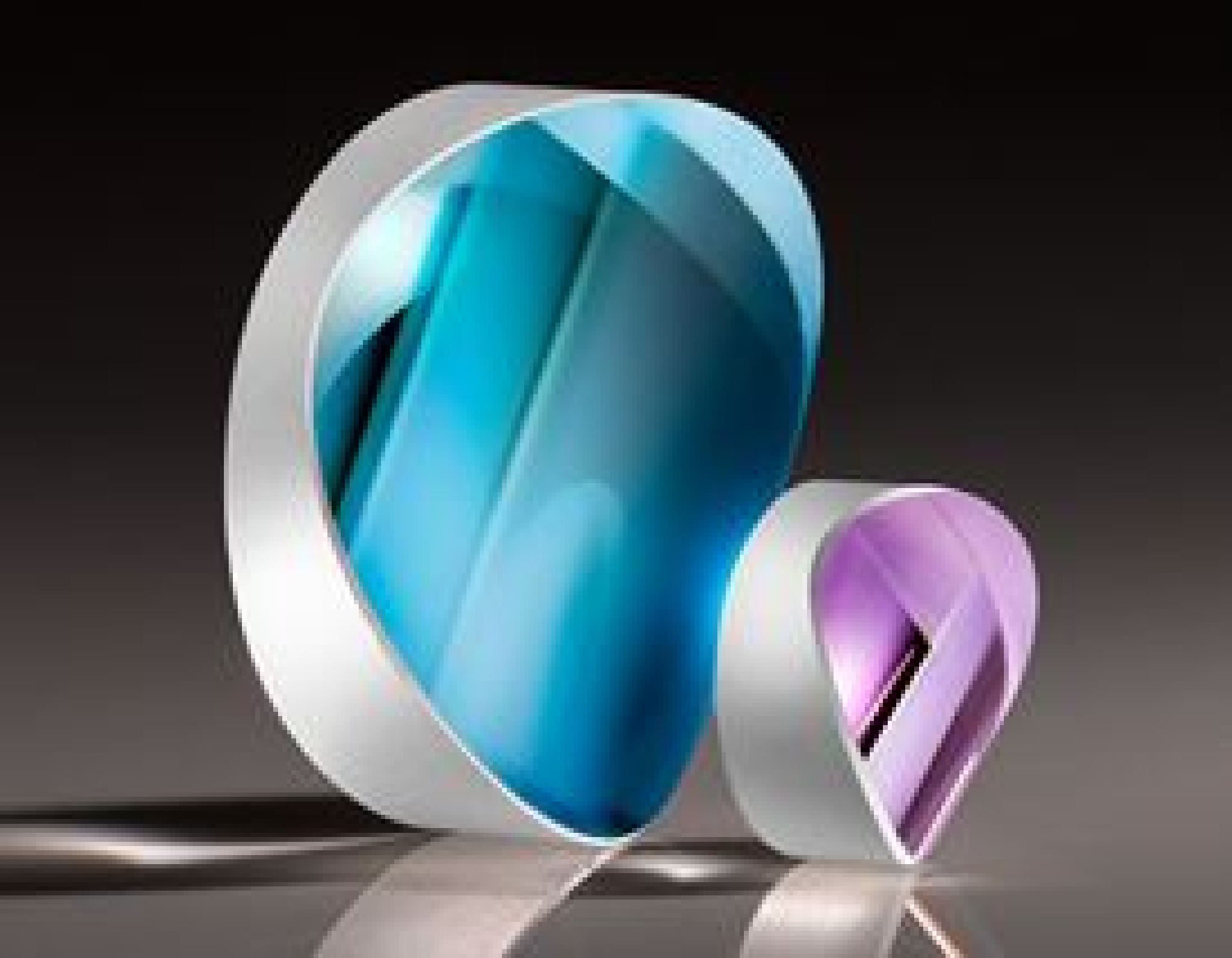

TECHSPEC Acylinder Lenses

Stock #86-036 [CONTACT US](#)



1



€855,00

ADD TO CART

Qty 1-5
€855,00

Qty 6+
€684,00

Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
25.00 +0.0/-0.1

Effective Focal Length EFL (mm):
20.00

Substrate: ☐
[NSF](#)

f/#: 0.8
Numerical Aperture NA: 0.63
Coating: MgF ₂ (400-700nm)
Type: Acyliner Lens
Wavelength Range (nm): 400 - 700
Back Focal Length BFL (mm): 14.6
Center Thickness CT (mm): 9.00
Center Thickness Tolerance (mm): ±0.1
Clear Aperture (%): 90.00
Coating Specification: R _{avg} ≤1.75% @400 - 700nm
Edge Thickness ET (mm): 2.6
Focal Length Specification Wavelength (nm): 587.6
Surface Accuracy, RMS (µm): 1.0
Surface Quality: 60-40

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant