


TECHSPEC® 25mm Dia. x 50mm FL Uncoated, Double-Convex Lens

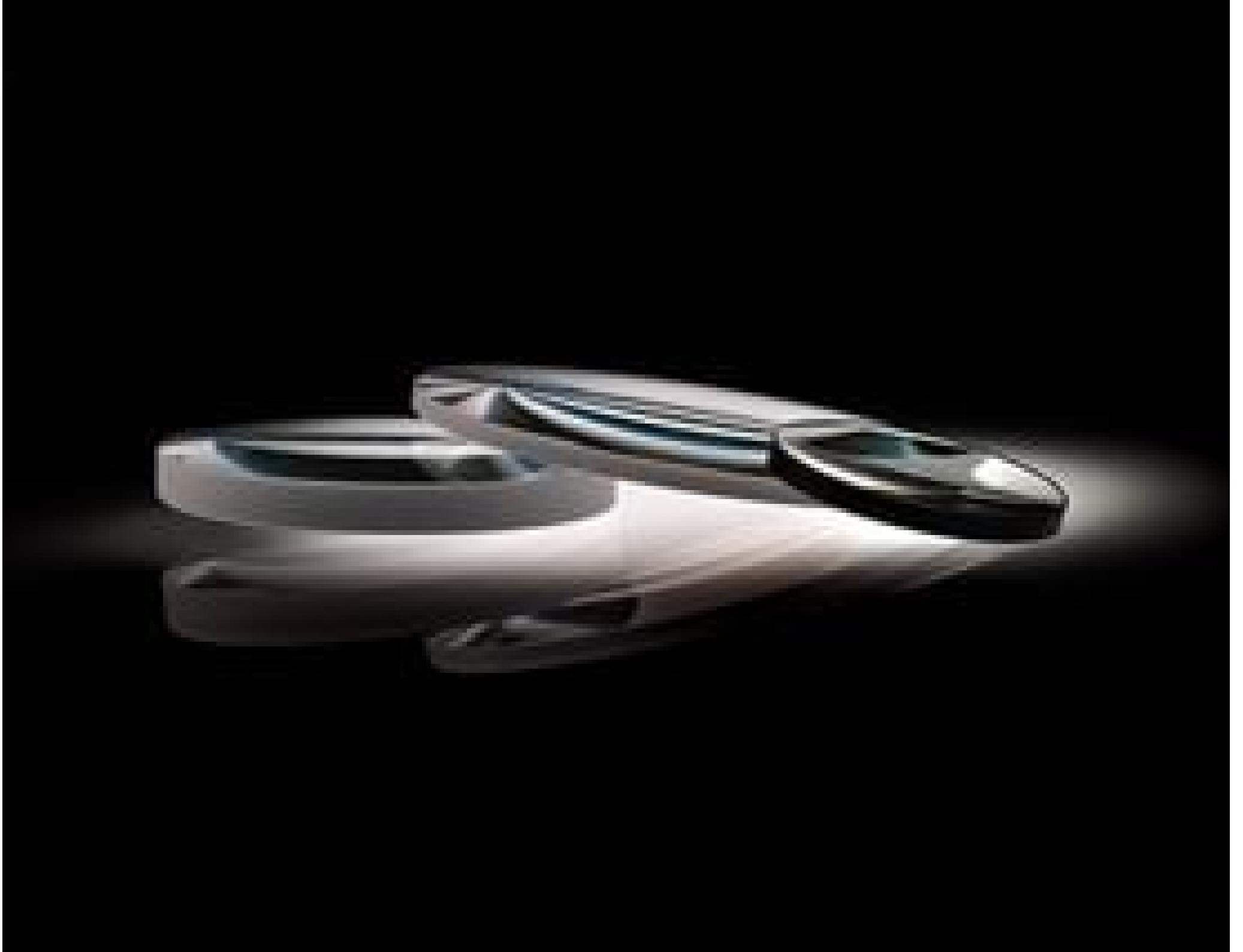

Stock #32-624 [CONTACT US](#)

[Other Coating Options](#)

1 **€31,50**

ADD TO CART

Qty 1-9

€31,50

Qty 10+

€28,25

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
25.00 +0.0/-0.025

Back Focal Length BFL (mm):
48.29

Effective Focal Length EFL (mm):
50.00

Coating:
Uncoated

Substrate:
[N-BK7](#)

Surface Quality:
40-20

Power (P-V) @ 632.8nm:
1.5λ

Irregularity (P-V) @ 632.8nm:
λ/4

Centering (arcmin):
<1

Bevel:
Protective bevel as needed

Center Thickness CT (mm):
5.00

Center Thickness Tolerance (mm):
±0.10

Edge Thickness ET (mm):
1.88

Radius R₁=R₂ (mm):
50.80

Clear Aperture CA (mm):
24.00

f#:
2.00

Focal Length Specification Wavelength (nm):
587.6

Focal Length Tolerance (%):
±1

Numerical Aperture NA:
0.25

Type:
Double-Convex Lens

Wavelength Range (nm):
350 - 2200

Regulatory Compliance

RoHS 2015:
[Compliant](#)

Certificate of Conformance:
[View](#)

Reach 235:
[Compliant](#)
