


[All Products](#) / [Microscopy](#) / [Magnifiers](#) / [Contact Reticles](#) / [Thickness and Hole Gauge Scale Contact Reticles](#)

[See all 5 Products in Family](#)

26mm Diameter, English Hole Gauge, Contact Reticle

26mm Diameter, English Hole Gauge, Contact Reticle

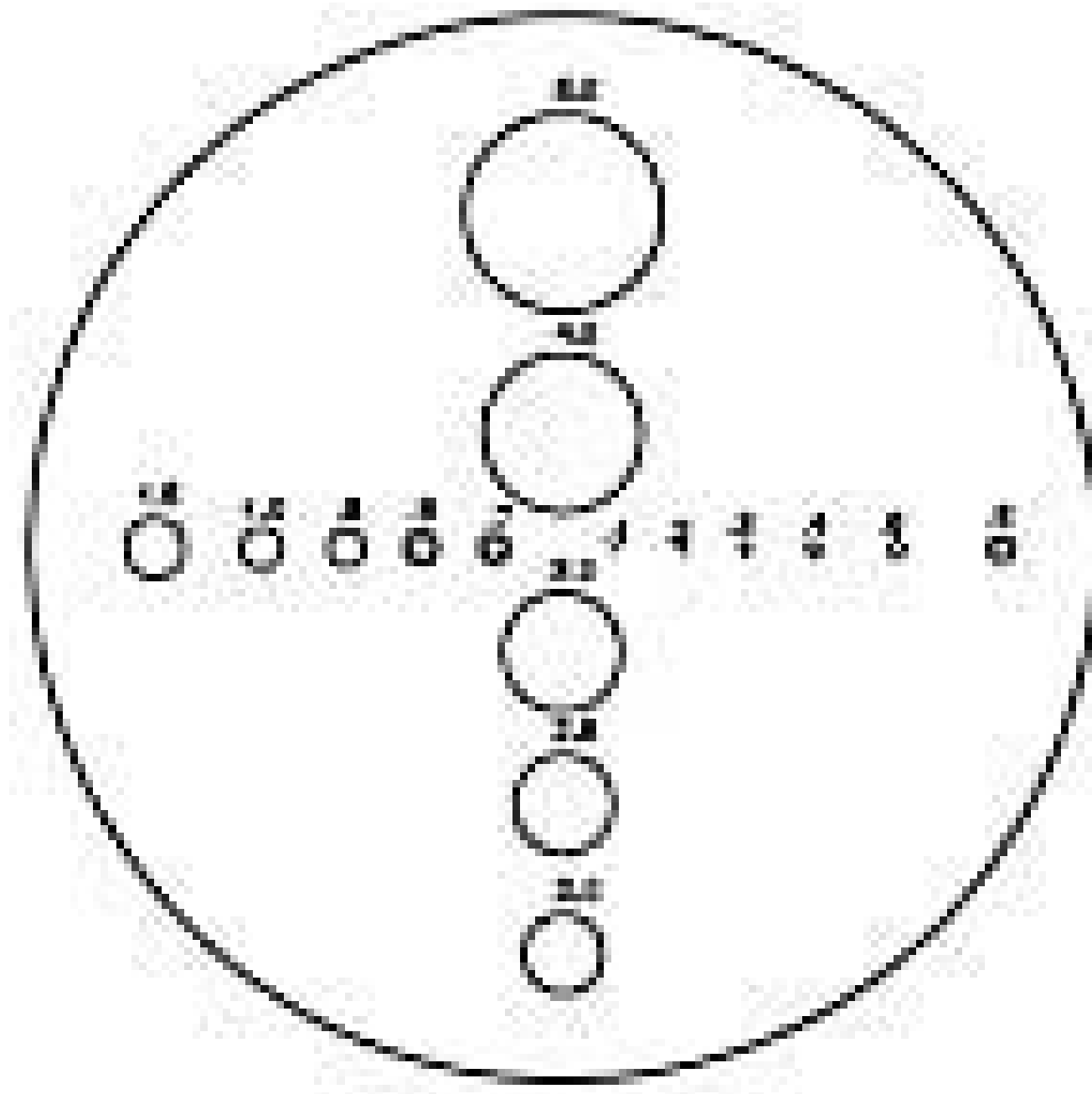

Hole Guage

Stock #64-853 3-4 DAYS

$\ominus$ 1 $\oplus$

€67,00

ADD TO CART

Qty 1-4

€67,00

Qty 5+

€62,90

Volume Pricing

[Request Quote](#)

! Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
26.00 ±0.125

Angle Tolerance (arcsec):
 ± 1

Line Thickness (μm):
25.00

Surface Quality: 60-40
Thickness (mm): 1.50
Thickness Tolerance (mm): ±0.10
Type: English Hole Gauge
Line to Line Accuracy (µm): ±2
Bevel: Protective bevel as needed
Parallelism (arcsec): <30
Centering (mm): 0.25
Line Thickness Tolerance (µm): ±13
Surface Flatness (P-V): 3 - 4λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View
