


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

2.8mm Two-Element Segmented Photodiode

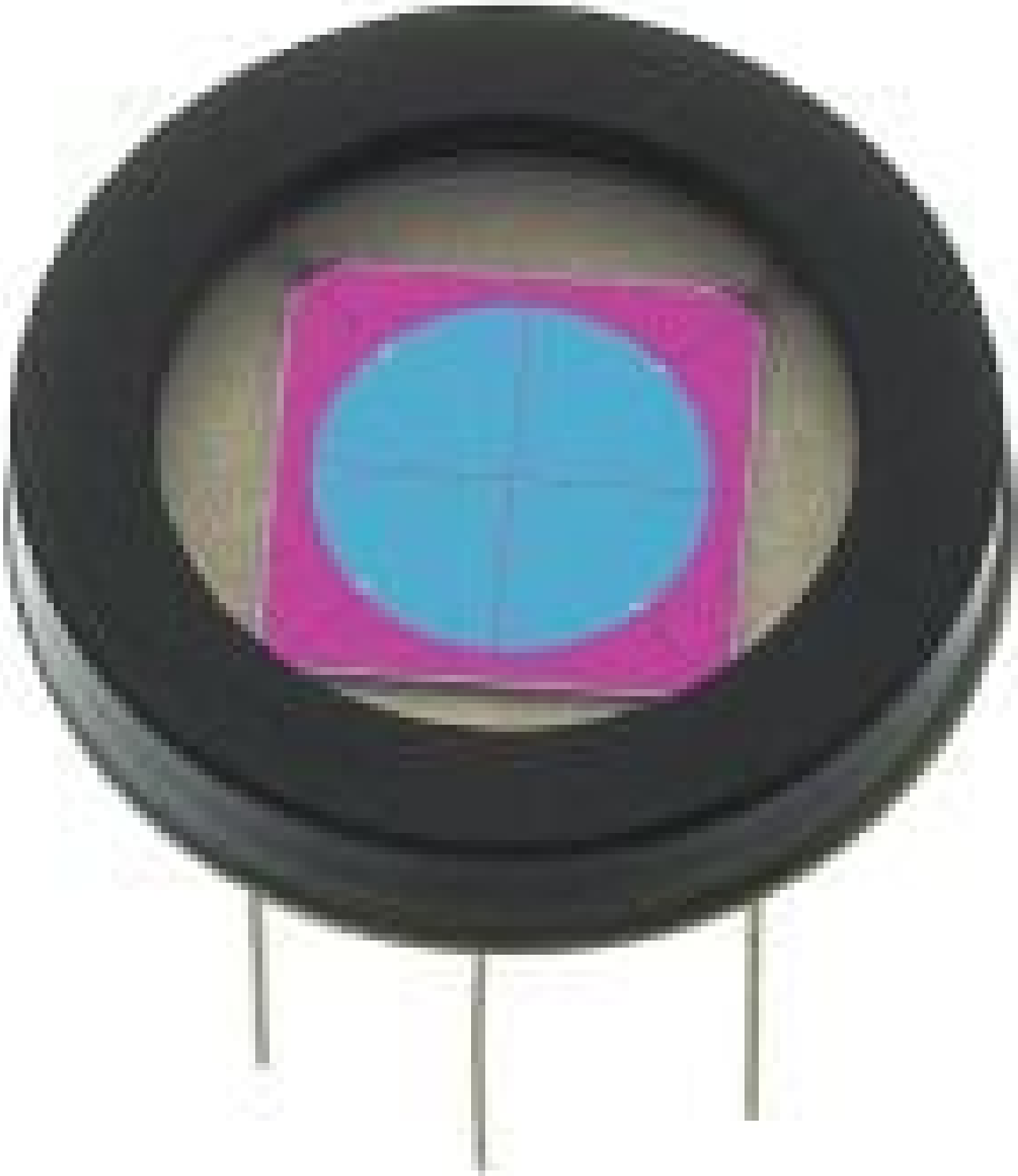

Stock #84-611 3-4 DAYS

-

1

+

 €72,00

ADD TO CART

Qty 1-4

€72,00

Qty 5+

€64,00

Volume Pricing

[Request Quote](#)

 Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Operating Temperature (°C):
-40 to 100

Size of Active Area (mm):
0.6 x 4.6

Storage Temperature (°C):
-55 to 125

Rise Time (ns):

4.00
Responsivity @ 970nm (AW): Minimum: 0.6 Typical: 0.65
Capacitance @ V_R=-10V (pF): 7.00
Active Area (mm²): 2.8
Noise Equivalent Power NEP (W/ Hz^{1/2}): 9.9 x 10 ⁻¹⁵ @ -10 V, 970nm
Maximum Reverse Voltage (V): 30.00
Model Number: SPOT-3D
Connector: 41 / TO-5
Dark Current @ V_R=-10V (nA): Maximum: 2 Typical: 0.13
Element Gap (mm): 0.025

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View