


2" x 2" Sq., Plastic Optical Window

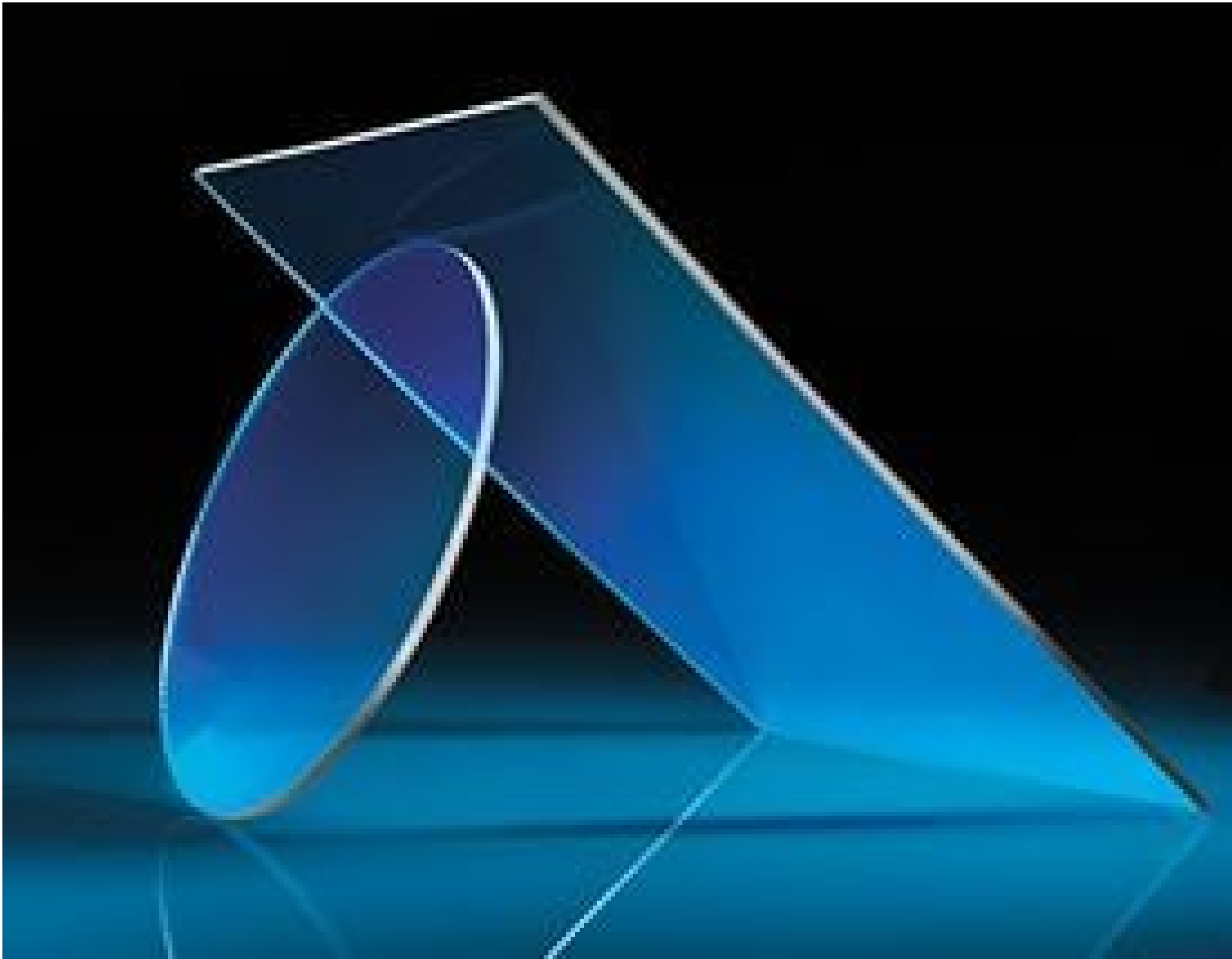

Stock **#43-927** ☐ In Stock

-

1

+

€27,00

ADD TO CART

Qty 1-49
€27,00
Qty 50+
€21,50
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Abbe Number (v_d):
57.00

Dimensions (mm):
50.80 x 50.80

Dimensions (inches):
2.00 x 2.00

Thickness (mm): 1.50 ±0.15
Coating: Uncoated
Density (g/cm³): 1.320
Index of Refraction n_d: 1.501
Operating Temperature (°C): 100 Continuous, 130 for 1 hour
Substrate: Thermoset ADC (CR-39®)
Transmission (%): >90 (typical)
Type: Protective Window
Wavelength Range (nm): 400 - 1500
Length (mm): 50.80
Width (mm): 50.80

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View