


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

TECHSPEC® 30 X 30mm Protected Silver, λ /20 Mirror

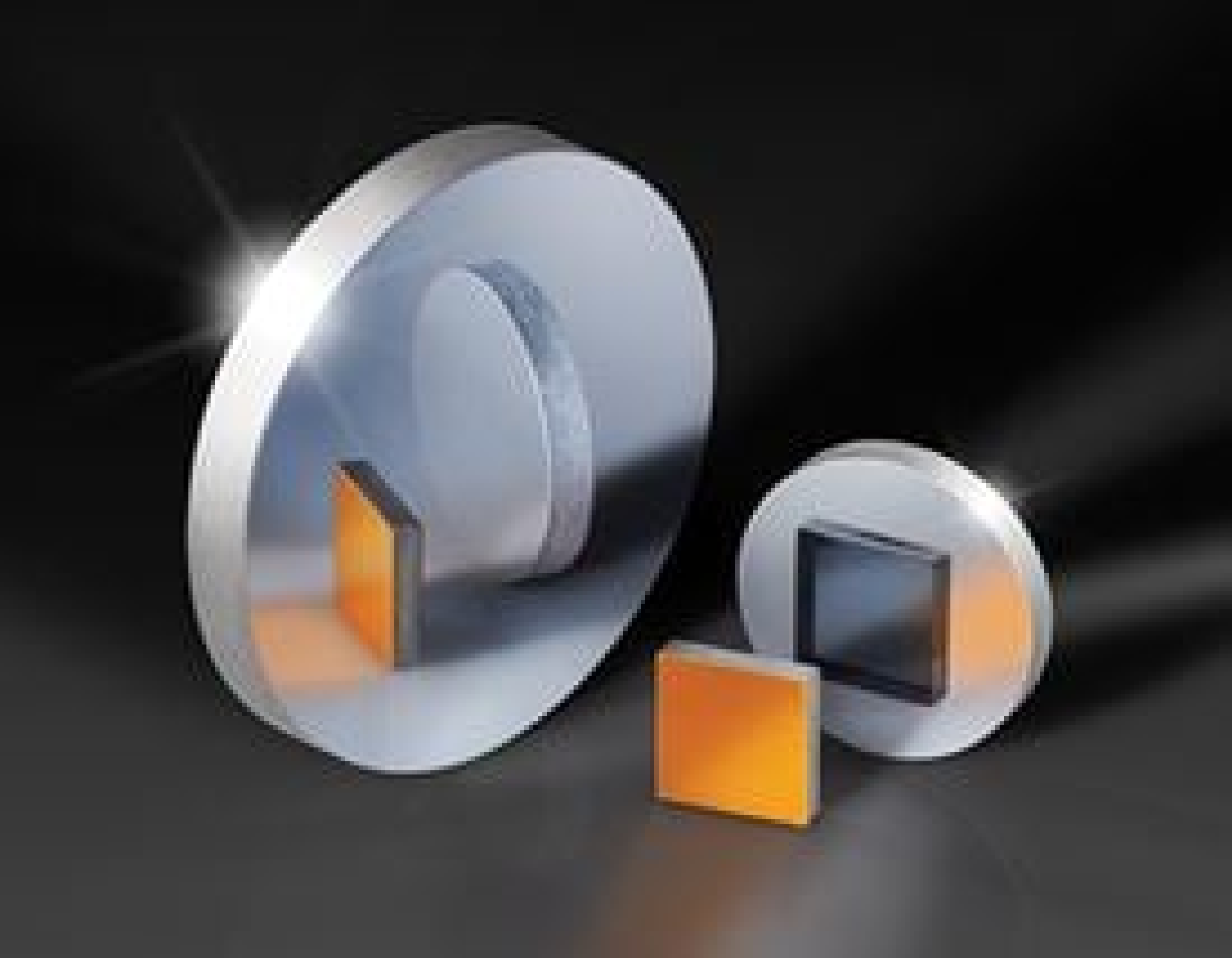

Stock #34-395 3-4 DAYS

1 €208,00

ADD TO CART

Qty 1-5

€208,00

Qty 6+

€166,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Flatness (P-V):
 λ /20 (flatness pre-coating)

Substrate: [Fused Silica](#) (Corning 7980)

Back Surface:
Commercial Polish

Surface Quality: 20-10
Dimensions (mm): 30.0 x 30.0 +0.00/-0.20
Coating Specification: R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm
Coating: Protected Silver (450-10000nm)
Coating Type: Metal
Clear Aperture (%): 90.00
Edges: Ground, protective bevel as needed
Parallelism (arcsec): 30.00
Thickness (mm): 5.00
Type: Flat Mirror
Wavelength Range (nm): 450 - 10000
Length (mm): 30.00
Width (mm): 30.00

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant