

TECHSPEC[®] 30mm, Center Drive, Standard Top, 0.5" Travel, English Micrometer



Stock #66-387 2 In Stock

-

1

+

€438^{.00}

ADD TO CART

Volume Pricing	
Qty 1-2	€438,00 each
Qty 3+	€382,00 each
Need More?	Request Quote

Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Type:

English


Physical & Mechanical Properties

Type of Movement:

Linear (X)

Guide System:


Crossed Roller Bearing

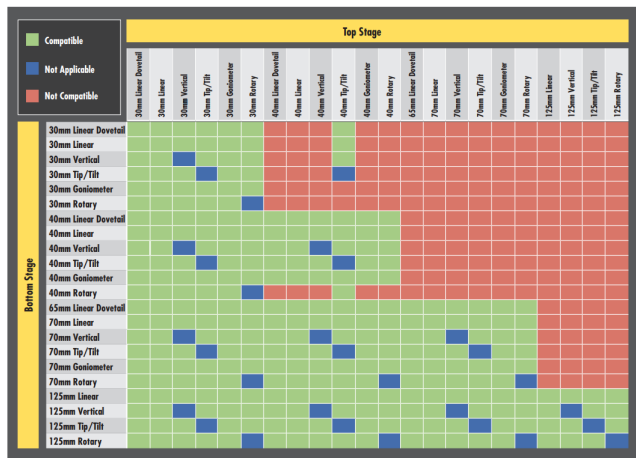

30mm Standard-Top Stages - Center Drive




30mm Standard-Top Stages - Side Drive

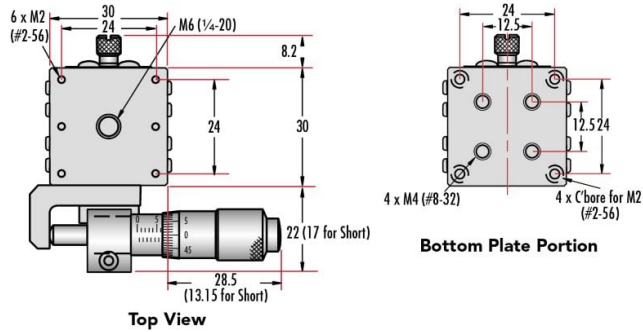

40mm Standard-Top Stages - Center Drive




40mm Standard-Top Stages - Side Drive

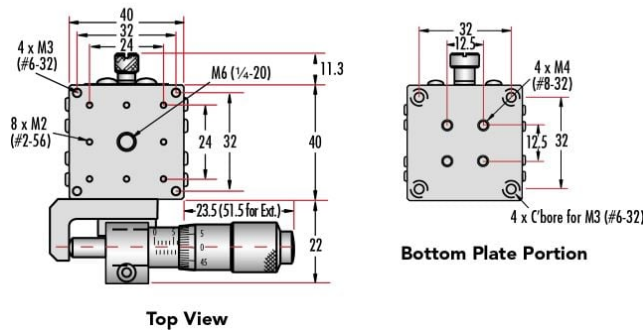

70mm Standard-Top Stages - Center Drive



70mm Standard-Top Stages - Side Drive

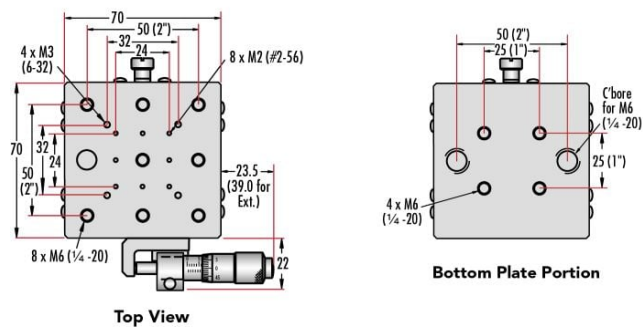

125mm Standard-Top Stages - Center Drive



125mm Standard-Top Stages - Side Drive

