

30mm, Multiple Filter Holder



#55-006

Stock **#55-006** 3 In Stock

-

1

+

€104⁰³

ADD TO CART

Volume Pricing	
Qty 1-9	€104,03 each
Qty 10-25	€93,63 each
Qty 26-49	€88,58 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

SPECIFICATIONS

General

FixedType:

Circular	Type of Optics:
Note:	
Available in Quick Start Kit: #17-532	
Physical & Mechanical Properties	
Construction:	
Black Anodized Aluminum	
Max. Thickness of Compatible Optics (mm):	
5.0	
Threading & Mounting	
Size of Compatible Optics (mm):	
30.0	
Compatible Post:	
M6 x 1.0	
Regulatory Compliance	
RoHS 2015:	
Compliant	
Certificate of Conformance:	
View	
Reach 247:	
Compliant	

PRODUCT DETAILS


- Allows Stacking of 3 or 5 Filters
 - Black Anodized Aluminum
 - [Posts](#) and [Post Holders](#) Required for Mounting
- Fixed/Multiple Filter Mounts are ideal for use with neutral density filters in stacking applications. Mounting cell holds filter with diameter "F" in place with a retainer ring. Mounting cell sits securely in filter holder. Fixed/Multiple Filter Mounts can also hold unmounted filters with diameter "A". A filter holder and filter cell are required for a complete stacking system, such as the one illustrated in the product image. These mounts are constructed of black anodized aluminum and are optimal for mounting 3 or 5 circular optics.
- [Posts](#) and [Post Holders](#) are required for mounting to a breadboard.

TECHNICAL INFORMATION


Stock No.	A	B	C	D	No. of Slots	No. of Cell Slots
#55-006	30mm	50mm	34mm	5mm	4	3
#55-007	50mm	70mm	44mm	5mm	5	5

Stock No.	F	G	H
#56-759	12.7mm	10.2mm	30mm
#55-008	25mm	22.5mm	30mm
#56-760	25.4mm	22.9mm	30mm
#55-009	50mm	47mm	52mm

Multiple Filter Holder

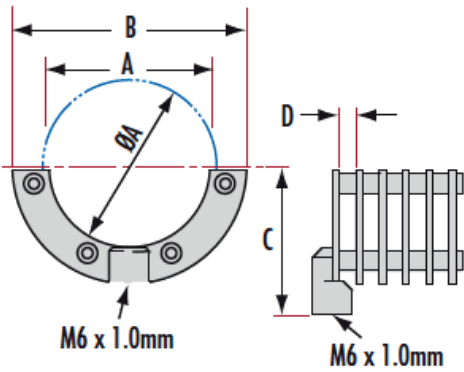

Mounting Cell

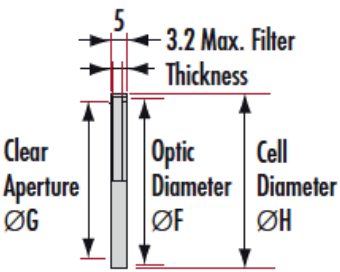

Units: mm