

[All Products](#) / [Optomechanics](#) / [Metric Dovetail Optical Rail Systems](#)

[See all 16 Products in Family](#)

30mm Precision Stage, Metric Dovetail Carrier



30mm Precision Stage, Metric Dovetail Carrier

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region: European Union

Submit

1

€119⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-9	€119,00 each
Qty 10+	€105,10 each
Need More?	Request Quote

Prices shown are exclusive of VAT/local taxes

Product Downloads

- STEP:step
- PDF Drawing:pdf
- IGES:igs
- eDrawing:eprt
- EO Spec Sheet
- [Download All](#)

General

Type: Metric

Note: Carrier

Physical & Mechanical Properties

Type of Movement: Linear (X)

Guide System: Dovetail

Length (inches): 1.18

Length (mm): 30.00

Construction: Black Anodized Aluminum

Hardware & Interface Connectivity

Type of Drive: Manual

Threading & Mounting

Mounting Threads: (8) M2 x 0.4, (1) M6 x 1.0

Regulatory Compliance

RoHS 2015: **Compliant**

Certificate of Conformance: [View](#)

REACH 241: **Compliant**

Product Details

- Wide Range of Carrier Length and Mounting Hole Options Available
- Low Profile Design with Smooth Movement
- Increased Stability and <1mrad Straight Line Accuracy

Dovetail Optical Rail Systems are designed for easy and stable installation and positioning of various optical components along the same axis. The rails feature slotted holes that allow them to be fixed to standard ¼-20 TPI and M6 **breadboards or optical tables**. Carriers are available with different lengths and hole patterns to meet various mounting needs including options that are directly compatible with our **TECHSPEC® Manual Stages** for precision alignment. Carriers utilize a unique two-piece design to prevent the locking screws

from contacting the rail and to allow easy attachment and removal. All Dovetail Optical Rail System parts are constructed of black anodized aluminum to minimize stray reflections or glare.

Note: Rails and carriers are sold separately.

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.


Select Your Country/Region:

Stock No.	L	A	B	C	D	# Slots	# C'bores
#54-401	12	6	4	—	—	3	—
#54-402	36	18	16	4	6	5	2

Related Products



Vertical Translation Stages

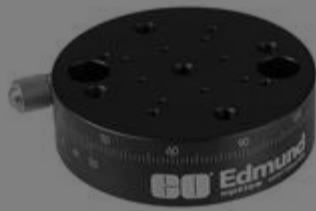

Rotary Stages



Goniometers



English and Metric Breadboards

Frequently Purchased Together




#32-974 - 50.0mm Dia. x 150.0mm FL, Uncoated, Plano-Convex Lens
€49,50

Qty



#47-207 - 1.0 OD 25mm Diameter UV-VIS ND Filter
€131,00

Qty

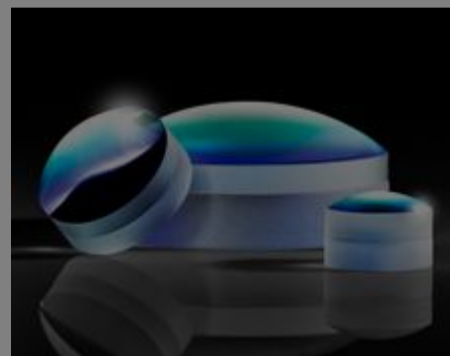

#49-665 - 25mm Diameter x 50mm EFL Aspherized Achromatic Lens
€149,95

Qty



#53-355 - English Post Pivot Base
€23,00

Qty

Resources

Media Type

▶ VIDEO

Important Concepts for Selecting Manual

▶ VIDEO

Multi-Axis Translation Stage Configuration

▶ VIDEO

Multi-Axis Translation Stage Configuration

- Video
- FAQ
- Glossary
- Application Note

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region:

Translation
Stage
Specifications
to Know

How do I
mount a ball
bearing linear
translation...

? FAQ

Do you sell X-Z
translation
stages?

View More