


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

TECHSPEC® 30mm Protected Silver Coated, N-BK7 Right Angle Mirror

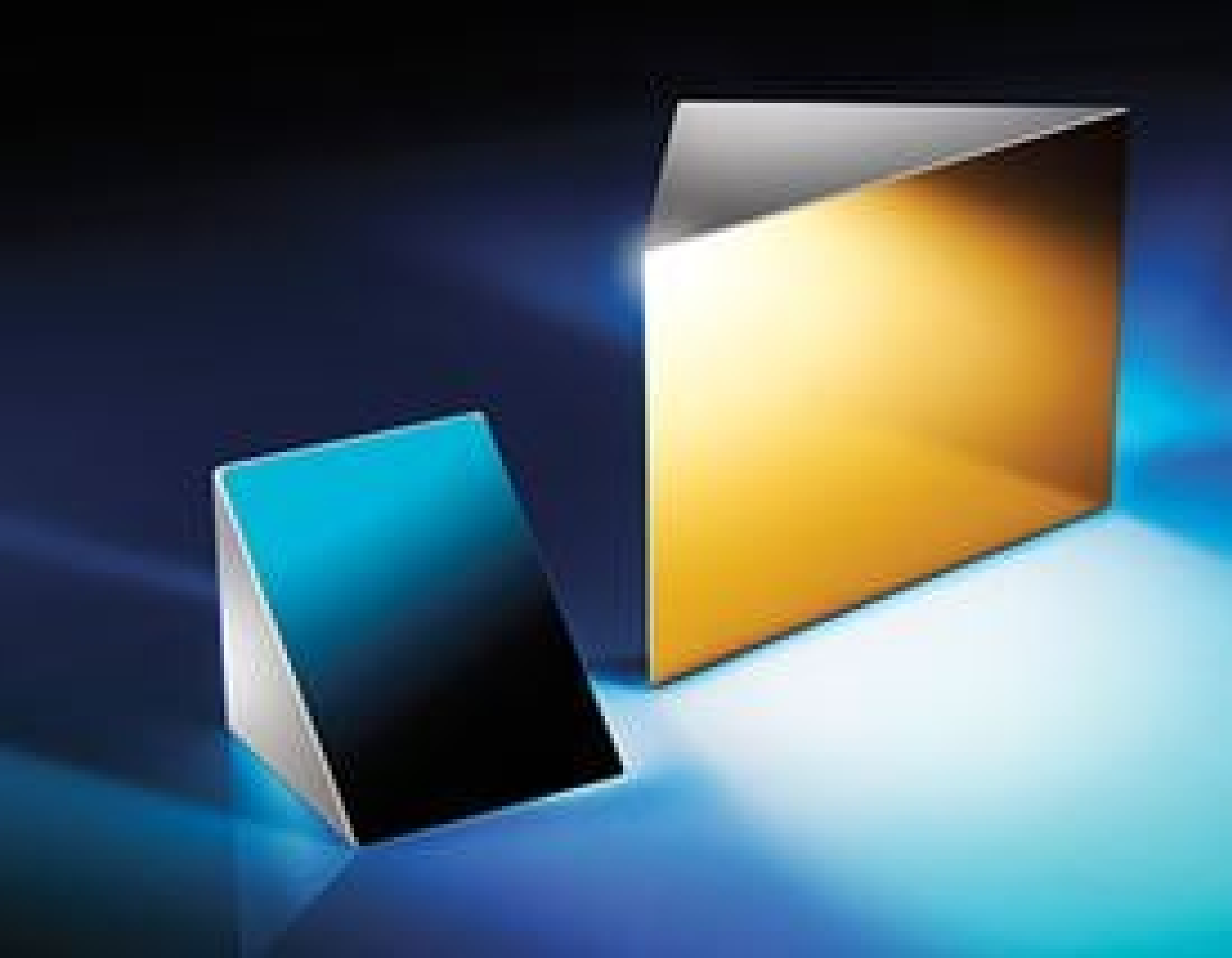

Stock **#89-631** [CONTACT US](#)

- 1 + **€170,00**

ADD TO CART

Qty 1-5
€170,00

Qty 6+
€136,00

Volume Pricing
Request Quote

 Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Flatness (P-V):
λ/4

Substrate: ☐
[N-BK7](#)

Surface Quality:
40-20

Length of Legs (mm): 30.00
Dimensional Tolerance (mm): ±0.1
Coating Specification: R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm
Coating: Protected Silver (450-10000nm)
Coating Type: Metal
Angle Tolerance (arcmin): ±2
Bevel: Protective bevel as needed
Clear Aperture CA (mm): 38.19 x 27.00
Length of Hypotenuse (mm): 42.40
Type: Right Angle Mirror
Wavelength Range (µm): 0.45 - 10
Wavelength Range (nm): 450 - 10000
Damage Threshold, Reference: ☐ 0.5 J/cm ² @ 532nm & 1064nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant