


20-40nm, 50.8mm Dia, EUV/IR Dichroic Filter

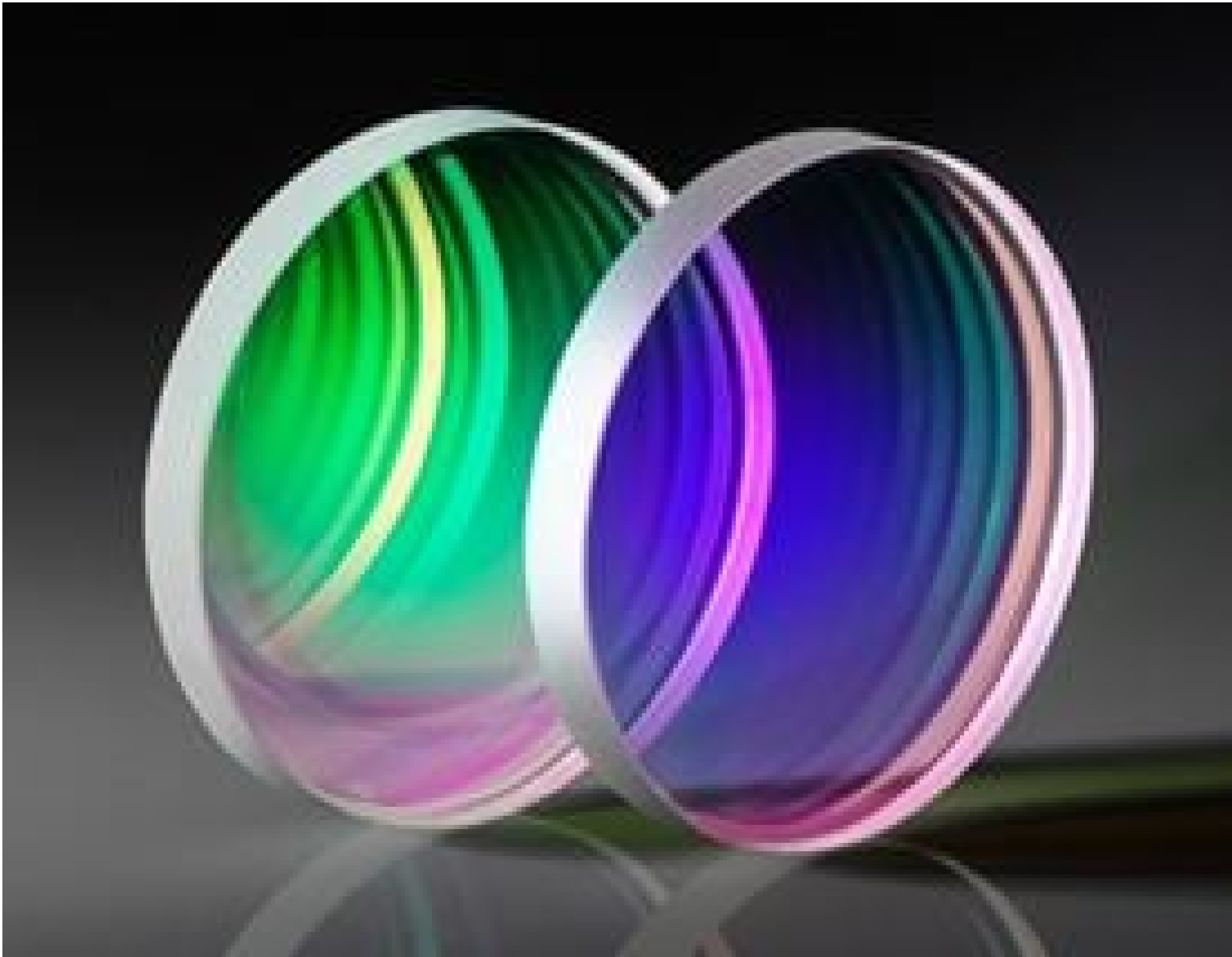

Extreme Ultraviolet (EUV) Dichroic Filters

Stock #18-280 3-4 DAYS

- 1 + **€4.950,00**

ADD TO CART

Qty 1+
€4.950,00

Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
50.80

Angle of Incidence (°):
78

Substrate: ☐
[Fused Silica](#) (Corning 7980)

Coating:
Dielectric Multilayer AR

Reflection (%):

>40
Surface Quality: 20-10
Thickness (mm): 5.08 ±0.1
Type: Dichroic Filter
Parallelism (arcmin): <5
Dimensional Tolerance (mm): +0.0/-0.2
Wavelength Range (nm): 20 - 40
Surface Figure, RMS: <λ/10 @ 633nm

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View