

34mm Diameter, UV Cut-Off Filter



Stock **#54-049** CLEARANCE **5 In Stock**

-

1

+

€14^{.95}

ADD TO CART

Volume Pricing	
Qty 1+	€14,95 each
Need More?	Request Quote

Prices shown are exclusive of VAT/local taxes

Product Downloads

General

UV Cut-Off Filter

Type:

Physical & Mechanical Properties

34.00 +0.0/-0.2

Diameter (mm):

2.00 ±0.2

Thickness (mm):

Optical Properties

390.00	Cut-On Wavelength (nm):
L-39	Glass/Filter Number:

Hoya L-39	Substrate: ☐
AR Coating	Coating:

Clear, Green Tint	Color:
80-50	Surface Quality:

>80 (avg)	Transmission (%):
350 - 2200	Wavelength Range (nm):

4 - 6λ	Surface Flatness (P-V):
--------	-------------------------

Environmental & Durability Factors

-15 to 70	Operating Temperature (°C):
-----------	-----------------------------


Regulatory Compliance

View	Certificate of Conformance:
----------------------	-----------------------------

Product Details

- Ideal for UV Applications
- For use with Longpass and Bandpass Filters
- Various Sizes Available

Technical Information

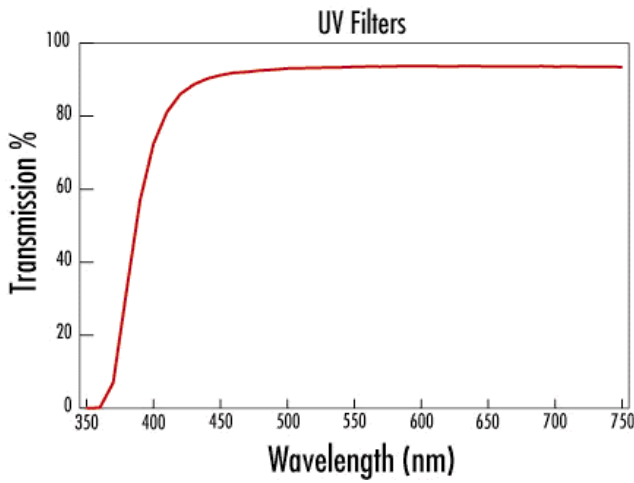

Compatible Mounts