


TECHSPEC® 35 x 35mm Enhanced Aluminum, 4-6λ Mirror

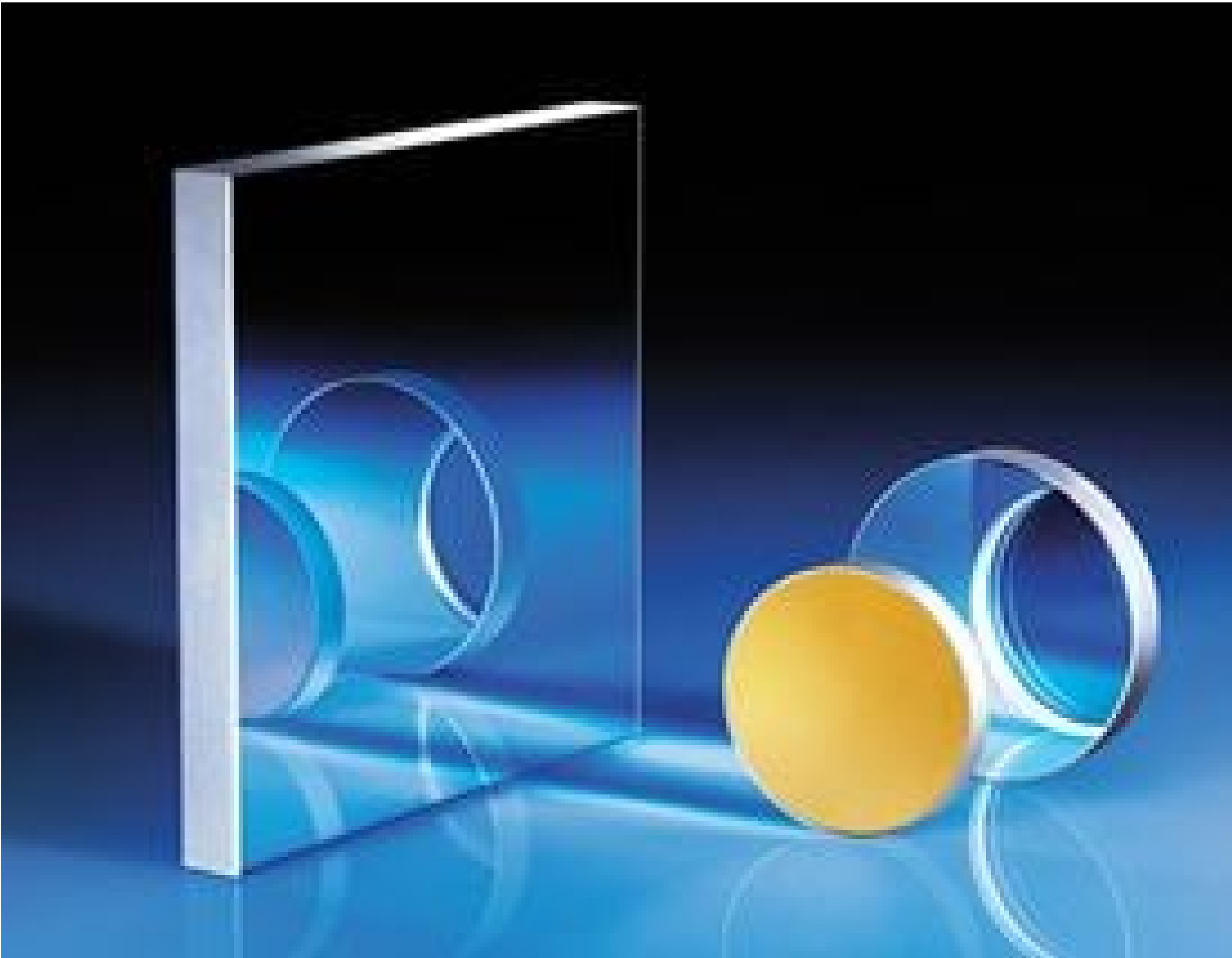

Stock **#45-519** ☐ In Stock

-

1

+

€30,00

ADD TO CART

Qty 1-5
€30,00

Qty 6+
€24,00

Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Surface Flatness (P-V):
4 - 6λ

Substrate: ☐
Float Glass

Surface Quality:
60-40

Dimensions (mm):

35.0 x 35.0
Dimensional Tolerance (mm): ±0.25
Coating Specification: R _{avg} ≥95% @ 450 - 650nm @ 45°
Coating: Enhanced Aluminum (450-650nm)
Coating Type: Metal
Clear Aperture CA (mm): 33.25 x 33.25
Edges: Seamed, 0.5mm Maximum Edge Chip
Thickness (mm): 3.00
Type: Flat Mirror
Wavelength Range (nm): 450 - 650
Length (mm): 35.00
Width (mm): 35.00
Damage Threshold, By Design: ☐ 0.2 J/cm ² @ 532nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant