


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

TECHSPEC® 40mm Dia Protected Gold, λ/20 Mirror

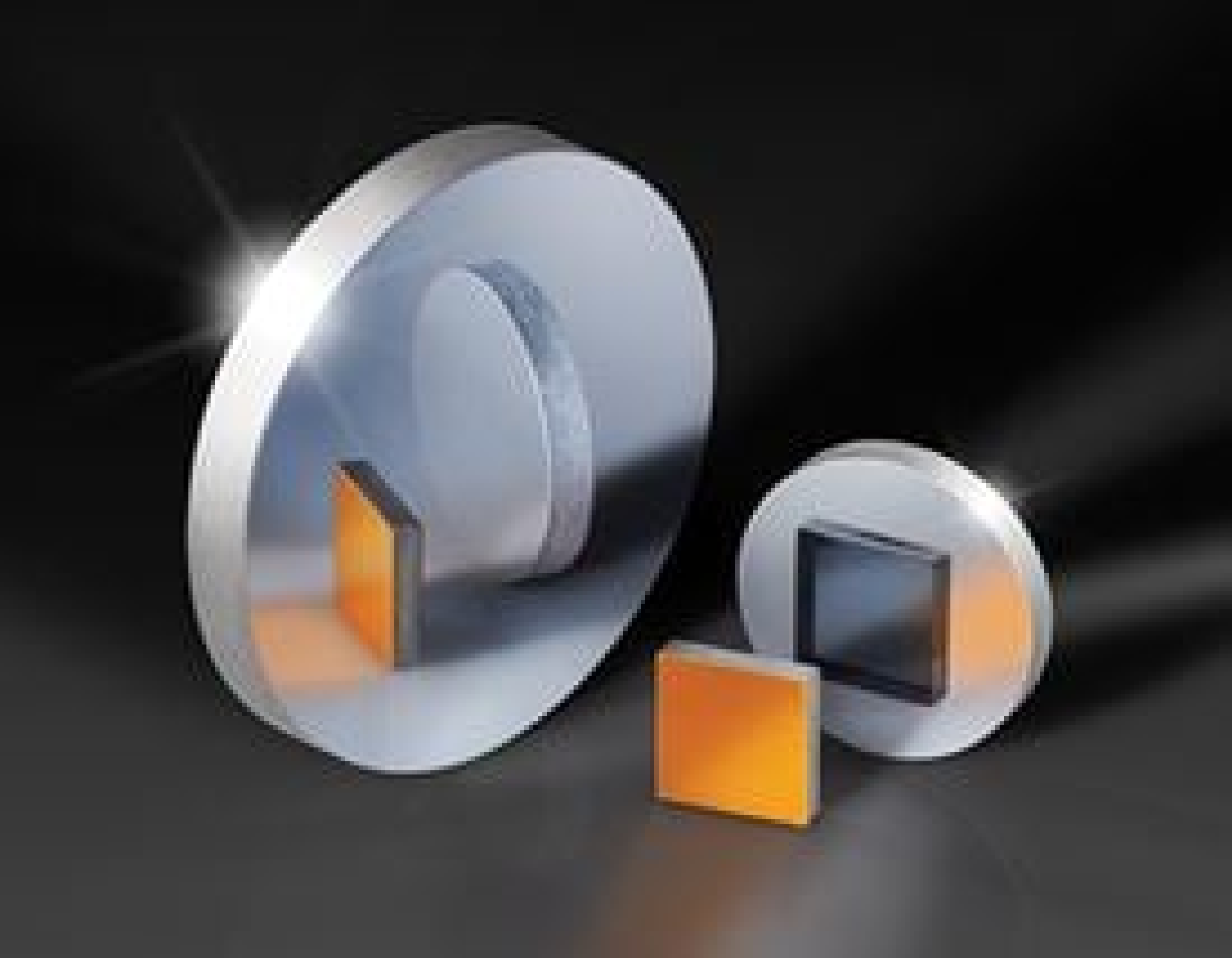

Stock #34-380 3-4 DAYS

1 €297,00

ADD TO CART

Qty 1-5

€297,00

Qty 6+

€237,50

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
40.00 +0.0/-0.20

Surface Flatness (P-V):
λ/20 (flatness pre-coating)

Substrate: ☐
[Fused Silica](#) (Corning 7980)

Back Surface: Commercial Polish
Surface Quality: 20-10
Coating Specification: R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm
Coating: Protected Gold (700-10000nm)
Coating Type: Metal
Clear Aperture (%): 90.00
Edges: Ground, protective bevel as needed
Parallelism (arcsec): 30.00
Thickness (mm): 5.00 ±0.20
Type: Flat Mirror
Wavelength Range (nm): 700 - 10000

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant