


TECHSPEC® 4.0mm Diameter x 5.0mm Length, N-BK7 Drum Lens

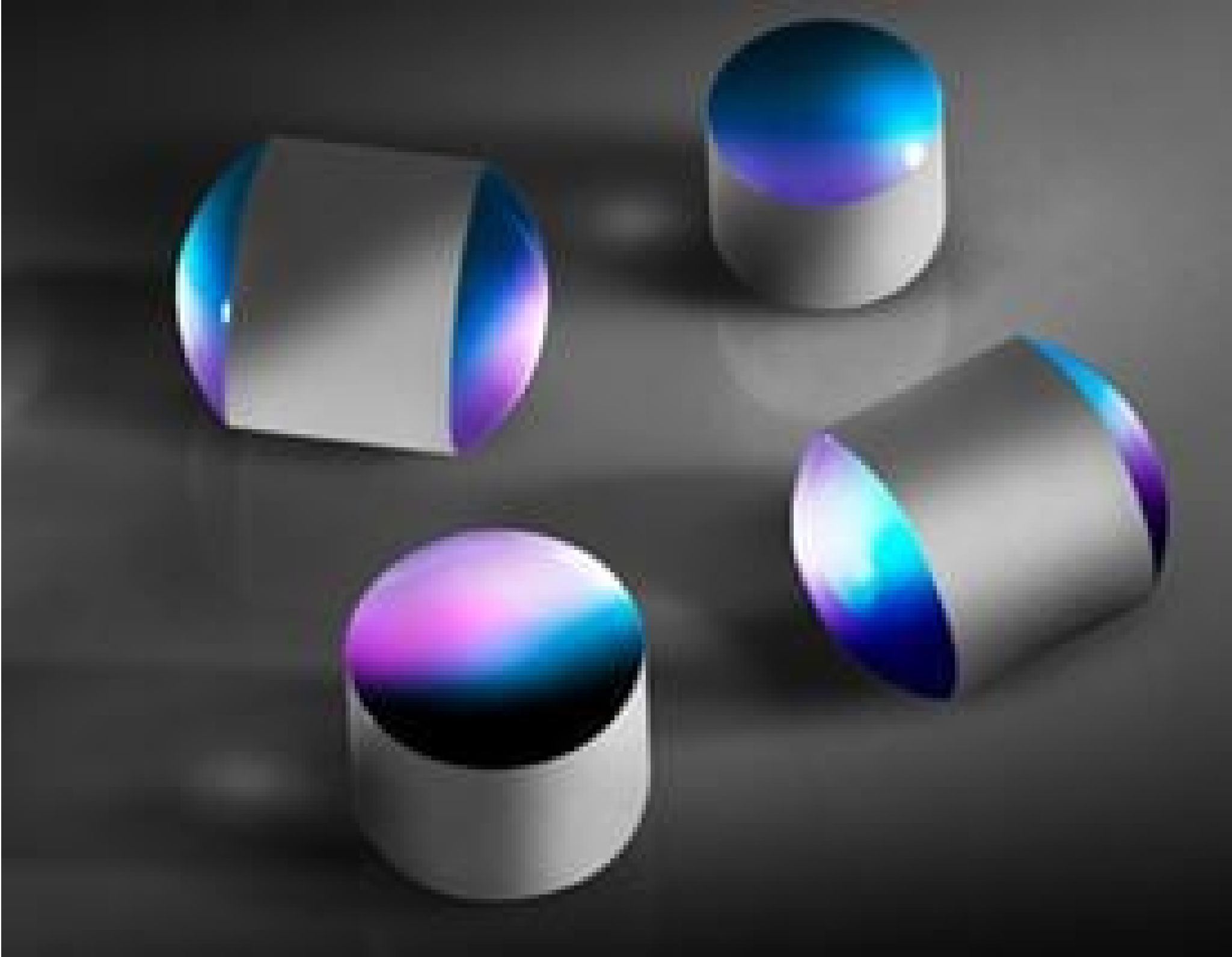

Stock **#45-551** CLEARANCE ☐ In Stock

- 1 + **€19,95**

ADD TO CART

Qty 1+
€19,95

Volume Pricing
Request Quote

! Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm): 4.00
Substrate: ☐ N-BK7
Coating: Uncoated
Type: Drum Lens

Wavelength Range (nm): 350 - 2200
Index of Refraction n_d: 1.517
Length (mm): 5.00
Length Tolerance (μm): ± 3
Radius R (mm): 2.50
Radius Tolerance (μm): $+0/-1.5$
Surface Quality: 40-20
Diameter Tolerance (μm): $+0/-50$

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View