

TECHSPEC[®] 40mm, Side Drive, Standard Top, English Stage



40mm, Side Drive, Solid Top Stage

Stock **#66-405** 3 In Stock

-

1

+

€391⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-2	€391,00 each
Qty 3+	€341,40 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

General

English

Type:


Physical & Mechanical Properties

Linear (X)

Type of Movement:

Crossed Roller Bearing

Guide System:

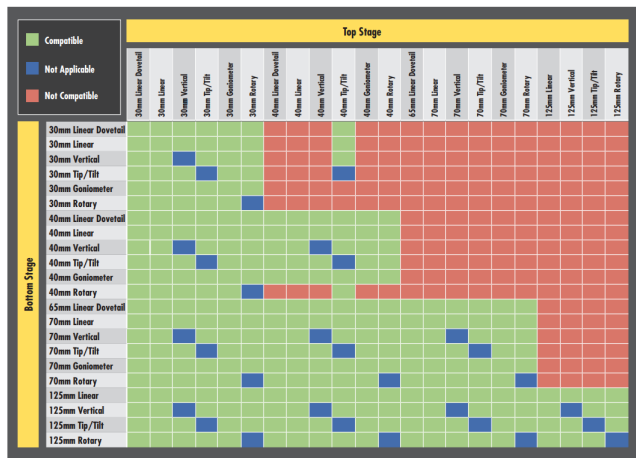

30mm Standard-Top Stages - Center Drive



30mm Standard-Top Stages - Side Drive



40mm Standard-Top Stages - Center Drive



40mm Standard-Top Stages - Side Drive



70mm Standard-Top Stages - Center Drive



70mm Standard-Top Stages - Side Drive



125mm Standard-Top Stages - Center Drive



125mm Standard-Top Stages - Side Drive

