


41 x 63.5mm AR Coated Float Glass Window

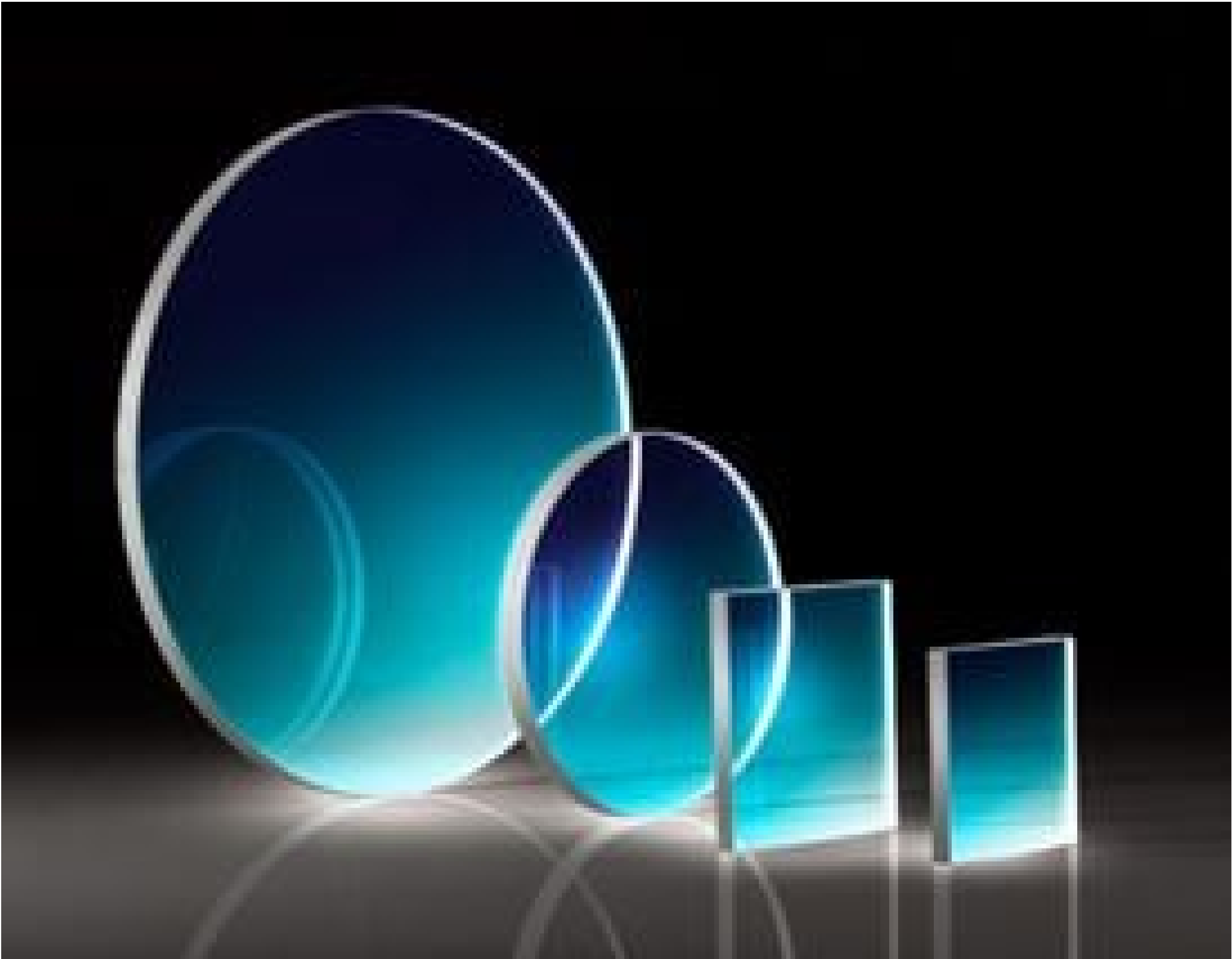

Stock **#32-740** 20+ In Stock

-

1

+

€25^{,24}

ADD TO CART

Volume Pricing	
Qty 1-5	€25,24 each
Qty 6-49	€22,66 each
Qty 50-99	€21,37 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

SPECIFICATIONS

General

Type:

Protective Window

Physical & Mechanical Properties	
41.00 x 63.50	Dimensions (mm):
3.00 (nominal)	Thickness (mm):
Fine Ground	Edges:
63.50	Length (mm):
41.00	Width (mm):
Optical Properties	
BBAR (400-700nm)	Coating:
Float Glass	Substrate:
4 - 6λ	Surface Flatness (P-V):
80-50	Surface Quality:
400 - 700	Wavelength Range (nm):
Regulatory Compliance	
Compliant	RoHS 2015:
View	Certificate of Conformance:
Compliant	Reach 247:

PRODUCT DETAILS

- Transmits Visible and Near Infrared Wavelengths
- Available Uncoated or with an Anti-Reflection Coating
- Variety of Sizes Available

Float Glass Optical Windows are optical glass with polished faces that are relatively parallel and are typically used as a protective element between two environments. Float glass readily transmits visible and near-infrared wavelengths and can be used in a wide variety of applications. Float Glass Optical Windows are versatile products offered in circular and rectangular options. They are available uncoated or with BBAR (Broadband Anti-Reflective) 400-700nm coating.

COMPATIBLE MOUNTS