

[See all 3 Products in Family](#)

4.5" Angle Mirror Mount



4.5" Angle Mirror Mount

Stock #36-482 **14 In Stock**

⊖ 1 ⊕ €378⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-4	€378,00 each
Qty 5-9	€353,20 each
Qty 10-25	€336,20 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Adjustable - Tip-Tilt **Type:**

Square or Rectangular **Type of Optics:**

3 **Number of Adjustment Screws:**

Physical & Mechanical Properties

Weight (lbs):
2.0

Construction:
Black Anodized Aluminum, Stainless Steel

Fine Tilt Angle (°):
8

Resolution (inches):
0.015

Fine Tip Angle (°):
8

Adjustment Screw Pitch (inches):
0.015

Threading & Mounting

Size of Compatible Optics (mm):
12.7 - 114.3

Mounting Plate Size (inches):
4.5 Sq.

Mounting Plate Screw Holes:
(49) 1/4-20 on 0.5" Center

Regulatory Compliance

RoHS 2015:
[Compliant](#)

Certificate of Conformance:
[View](#)


Reach 240:
[Compliant](#)

Product Details

- 3.0", 4.5", or 6.0" Square Mounting Surface
- Fine Adjustment Screws (64-Pitch) Allow for Tilting
- Mounting Plate with 1/4-20 Threaded Holes

Medium and Large Angle Mirror Mounts are available with a range of mounting plate sizes for mounting optical mirrors. These optical mirror mounts feature 64-pitch fine adjustment screws, allowing for precision tilting in two directions. Both square and rectangular optics can be mounted into these black anodized aluminum and stainless-steel mounts. Medium and Large Angle Mirror Mounts have two 1/4-20 through holes on their angle bases for easy mounting to optical tables or breadboards. These mounts are available in 3", 4.5", and 6" sizes.

Technical Information

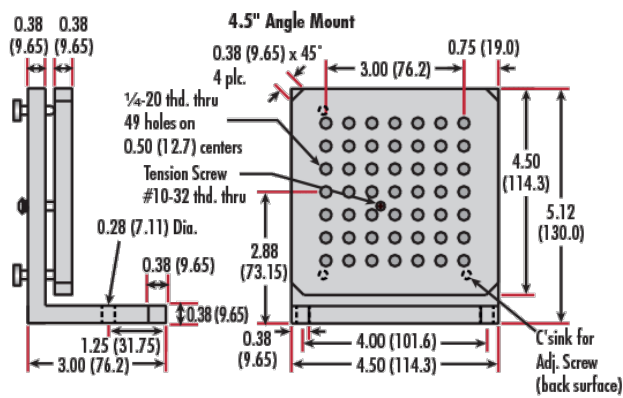

#36-482