


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

TECHSPEC® 45° AOI, 50.0mm Square, Cold Mirror

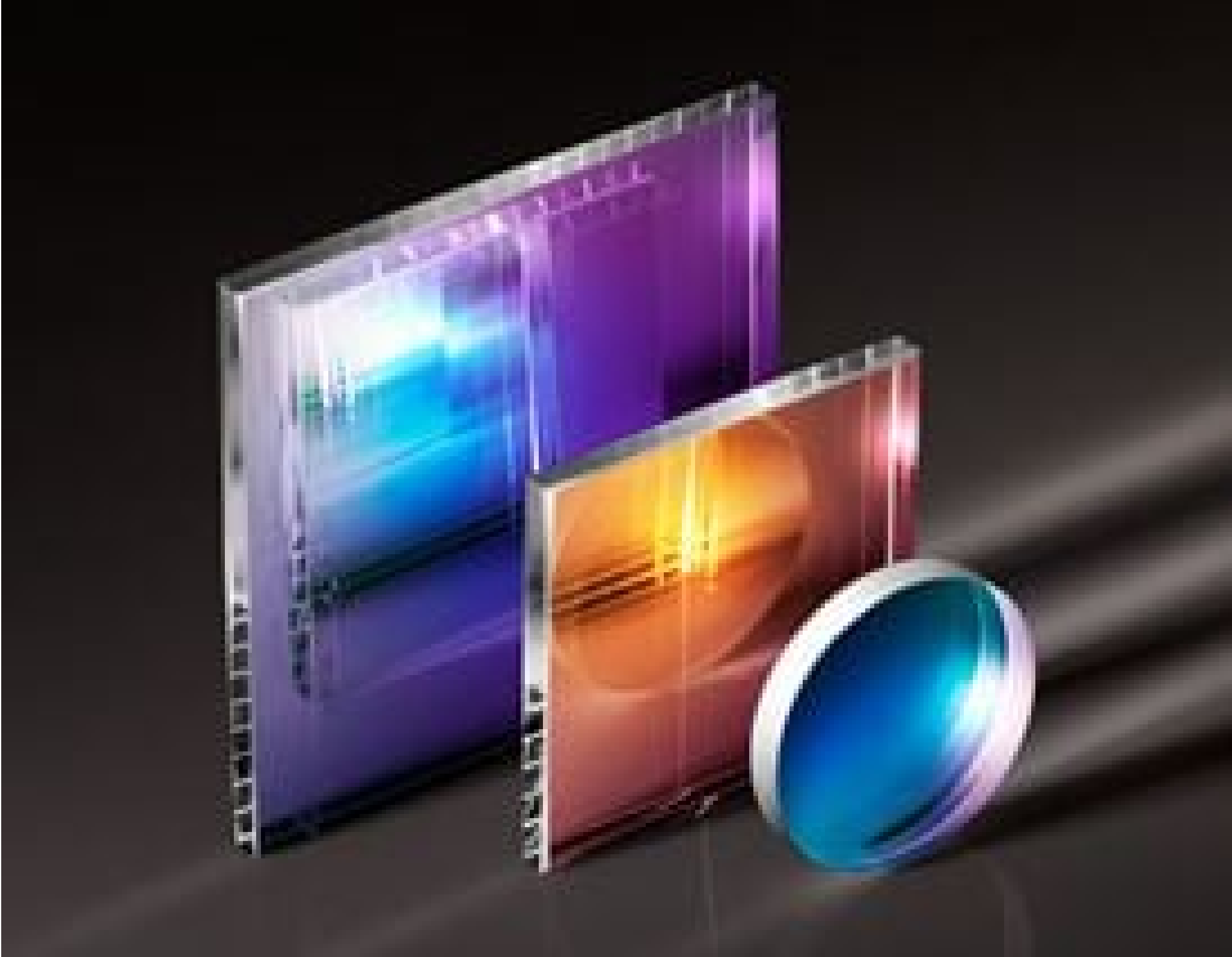

TECHSPEC High Performance Cold Mirrors

Stock #64-451 ☐ In Stock



1



€98,00

ADD TO CART

Qty 1-9

€98,00

Qty 10+

€86,20

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Angle of Incidence (°):
45

Coating:
Cold Mirror, 45°

Substrate: ☐
BOROFLOAT®

Dimensions (mm): 50.0 x 50.0
Surface Quality: 80-50
Thickness (mm): 3.30
Thickness Tolerance (mm): ±0.2
Transmission (%): Dichroic Filter
Type: Cold Mirror
Dimensional Tolerance (mm): +0.0/-0.2
Coating Specification: R _{avg} ≥95% @ 400 - 690nm and T _{avg} ≥90% @ 750 - 1200nm AR Coating: R _{avg} <1% @ 700 - 1150nm
Wavelength Range (nm): 425 - 1150
Surface Flatness (P-V): 4 - 6λ
Coating Type: Dielectric

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant