


47 x 51mm Laser Diode Mirror

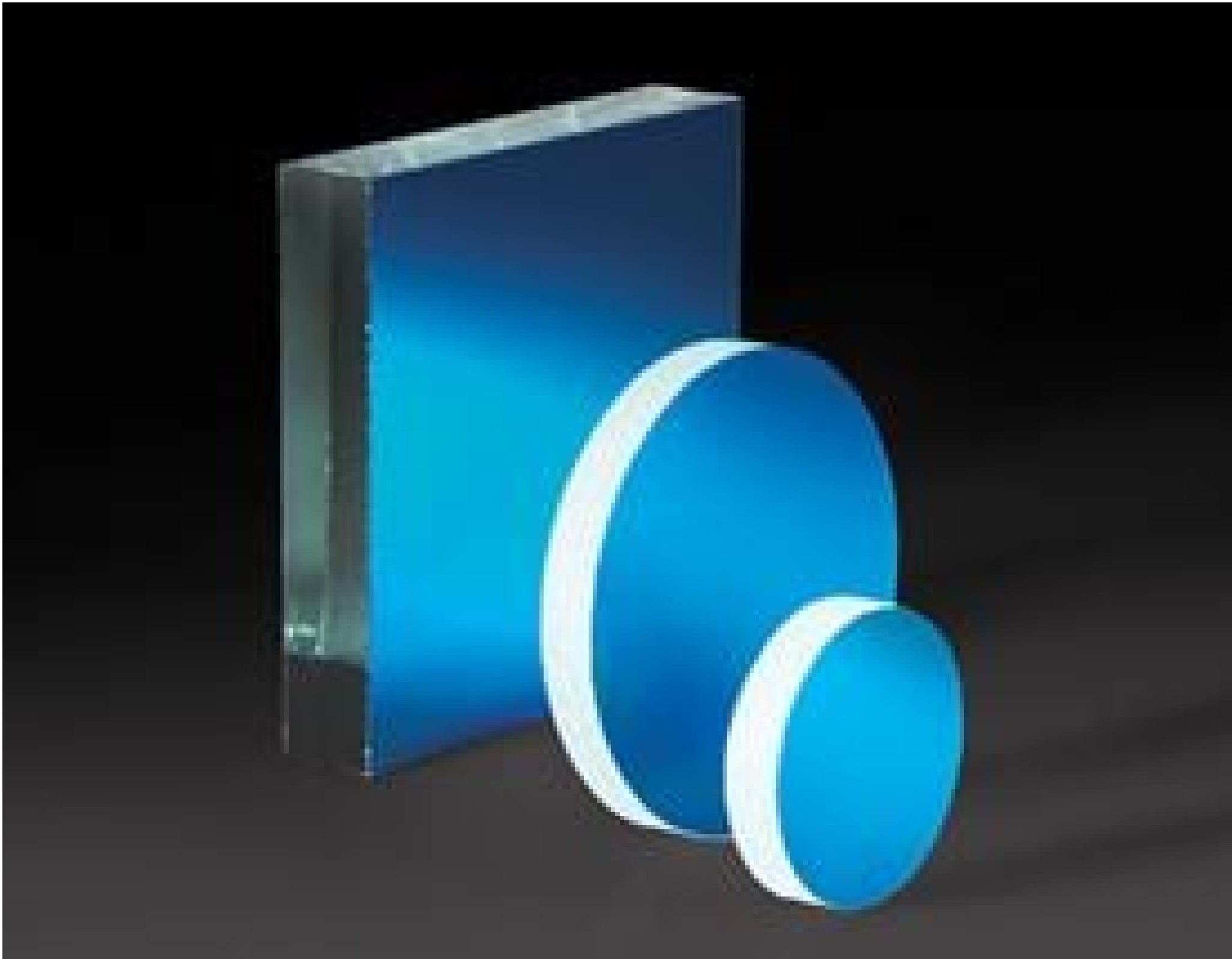

Stock **#31-496** ☐ In Stock

-

1

+

€36,50

ADD TO CART

Qty 1-10
€36,50
Qty 11+
€29,00
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Substrate: ☐
Float Glass

Surface Quality:
80-50

Dimensions (mm):
47.0 x 51.0

Dimensional Tolerance (mm):

±0.25
Coating Specification: R _{abs} >97% @ 633nm
Coating: Dielectric Mirror (500-700nm)
Coating Type: Dielectric
Design Wavelength DWL (nm): 633
Durability: ML-C-48497A
Thickness (mm): 6.35
Type: Flat Mirror
Length (mm): 51.00
Width (mm): 47.00

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant