


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

TECHSPEC® 4" Dia. Protected Aluminum, N20 Flat Fused Silica

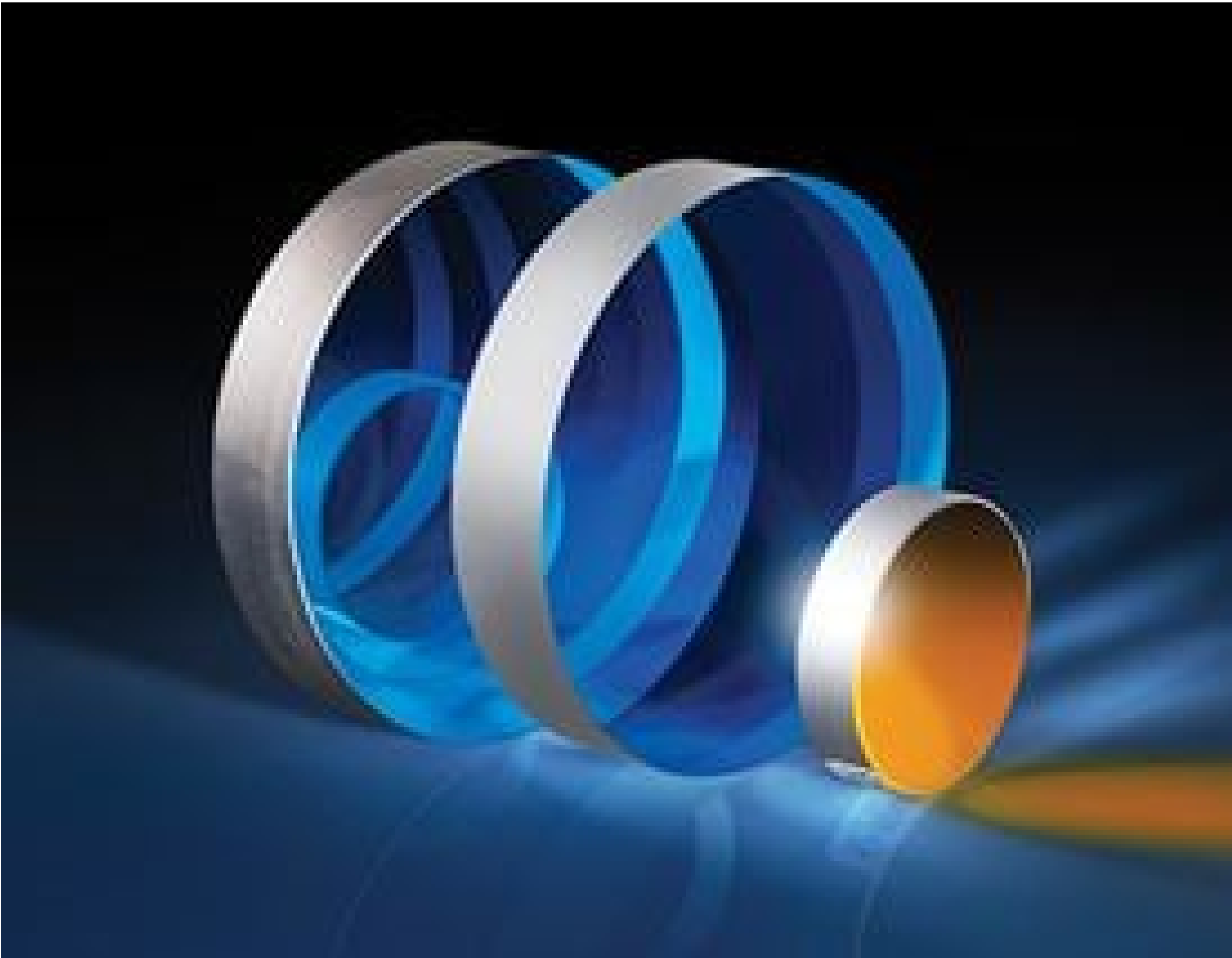

Stock #47-574-522 3-4 DAYS

1 €947,00

ADD TO CART

Qty 1-5

€947,00

Qty 6+

€852,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Flatness (P-V):
λ/20 (measured before coating)

Back Surface:
Commercial Polish

Surface Quality: 60-40
Diameter (mm): 101.60 +0.0/-1.02
Diameter Tolerance (inches): +0.0/-0.04
Substrate: □ Fused Silica (Corning 7980)
Coating Specification: R _{avg} >85% @400 - 700nm R _{avg} >90% @400 - 2000nm
Coating: Protected Aluminum (400-2000nm)
Coating Type: Metal
Clear Aperture CA (mm): 91.44
Note: Flatness is specified as Peak to Valley
Thickness (mm): 19.10 ±1.5
Thickness Tolerance (mm): ±1.5
Type: Flat Mirror
Wavelength Range (µm): 0.4 - 2
Wavelength Range (nm): 400 - 2000
Damage Threshold, Reference: □ 0.3 J/cm² @532nm & 1064nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant