


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

5 X 30° Diffusing Angle 8" x 8" Unmounted

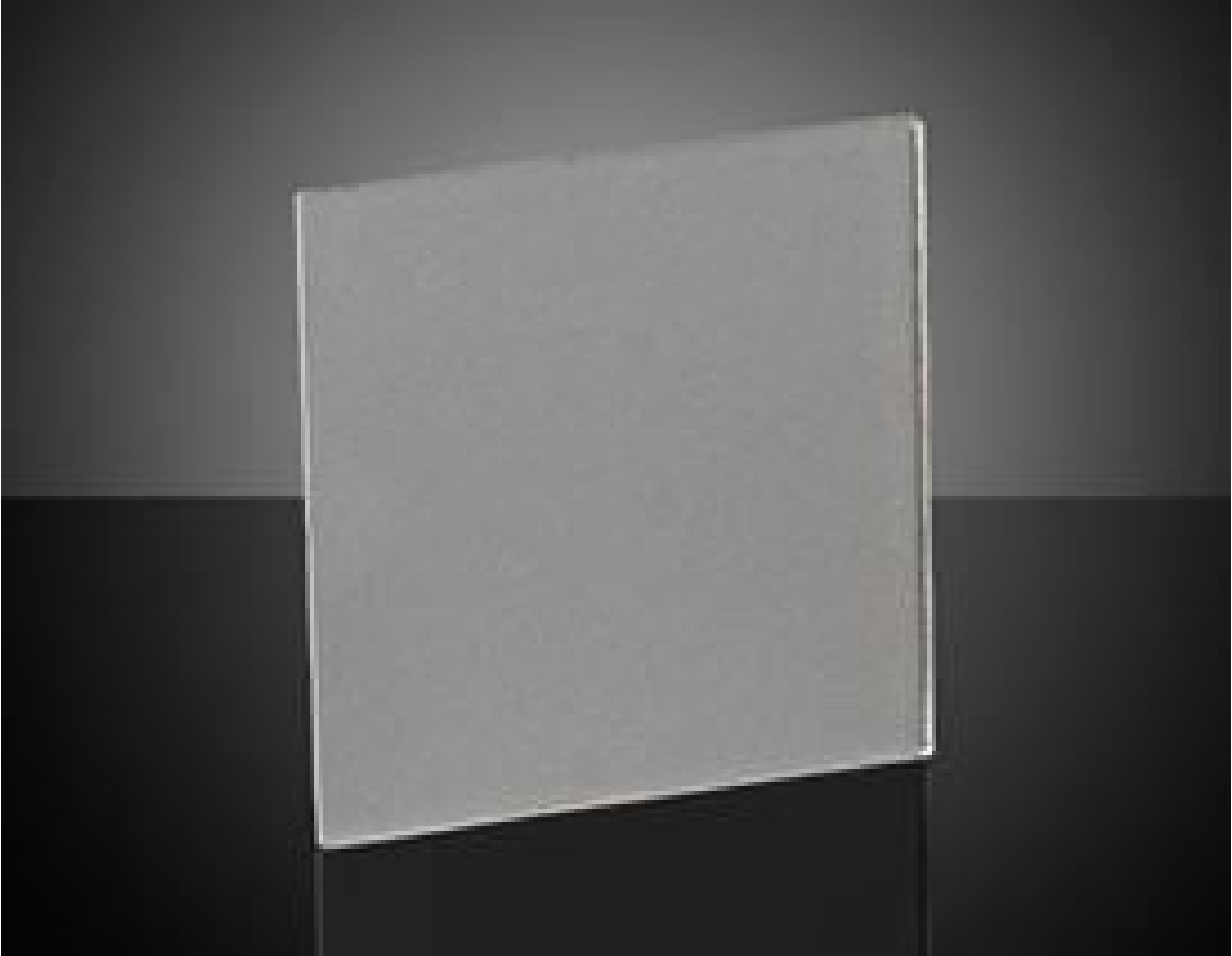

Stock #48-008 3-4 DAYS



1



€457,50

ADD TO CART

Qty 1+

€457,50

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Angle Tolerance (°):  
±1 x ±3

Diffusing Angle (°):  
5 x 30 (FWHM)

Dimensional Tolerance (mm):  
±0.5

Dimensions (inches):  
8 x 8

Dimensions (mm):  
203.20 x 203.20

|                                                                                                          |
|----------------------------------------------------------------------------------------------------------|
| <div>Operating Temperature (°C):<br/>-30 to +100 (Maximum of 240 Hours)</div>                            |
| <div>Substrate: <input type="checkbox"/><br/>Polycarbonate</div>                                         |
| <div>Thickness (mm):<br/>0.78</div>                                                                      |
| <div>Transmission (%):<br/>&gt;85</div>                                                                  |
| <div>Type:<br/>Holographic Diffuser</div>                                                                |
| <div>Wavelength Range (nm):<br/>400 - 700</div>                                                          |
| <div>Width (mm):<br/>203.20</div>                                                                        |
| <div>Construction:<br/>Unmounted</div>                                                                   |
| <div>Damage Threshold, By Design: <input type="checkbox"/><br/>0.22 J/cm² @ 1064nm, 10ns (typical)</div> |
| <div>Length (mm):<br/>203.20</div>                                                                       |

Regulatory Compliance

|                                                                 |
|-----------------------------------------------------------------|
| <div>RoHS 2015:<br/><a href="#">Compliant</a></div>             |
| <div>Certificate of Conformance:<br/><a href="#">View</a></div> |
| <div>Reach 233:<br/><a href="#">Compliant</a></div>             |