

In order to provide more accurate inventory information, please select your shipping country:


Select Your Country/Region: European Union



SUBMIT

50 X 50mm, Blue 455nm, MicroBrite High Intensity Edge-Lit Backlights

See More by [Advanced Illumination](#)

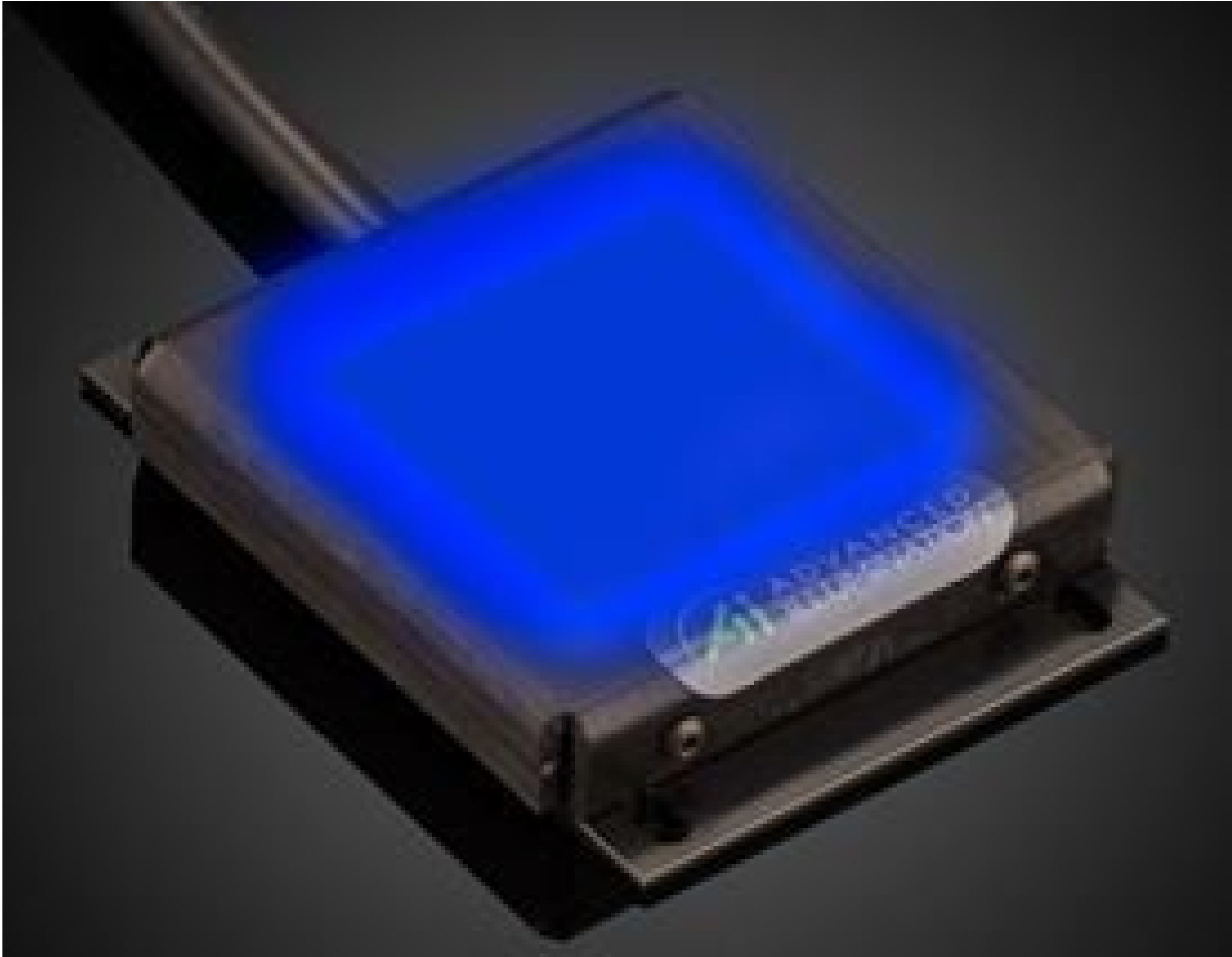

Stock #18-549 3-4 DAYS



1



€836,00

ADD TO CART

Qty 1+

€836,00

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Color:
Blue

Input Voltage (V):
24V

Model Number:
BT050050-455IC

Operating Temperature (°C):
0 - 60

Dimensions (mm):

70.3 x 54.71 x 11.33
Wavelength (nm): 455.00
Weight (g): 54.43
LED Lifetime (hours): 50,000
Active Area (inches): 1.40 x 1.35
Type of Illumination: LED Illuminator
Note: Optional Manual Intensity Adjustment #86-887 and #89-555 are Available
Manufacturer: Advanced Illumination
Geometry: Backlight
Illumination Mode: Constant
Environmental Rating: IP50

Regulatory Compliance

RoHS 2015: Exempt
Certificate of Conformance: View
Reach 233: Contains SVHC(s)