


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

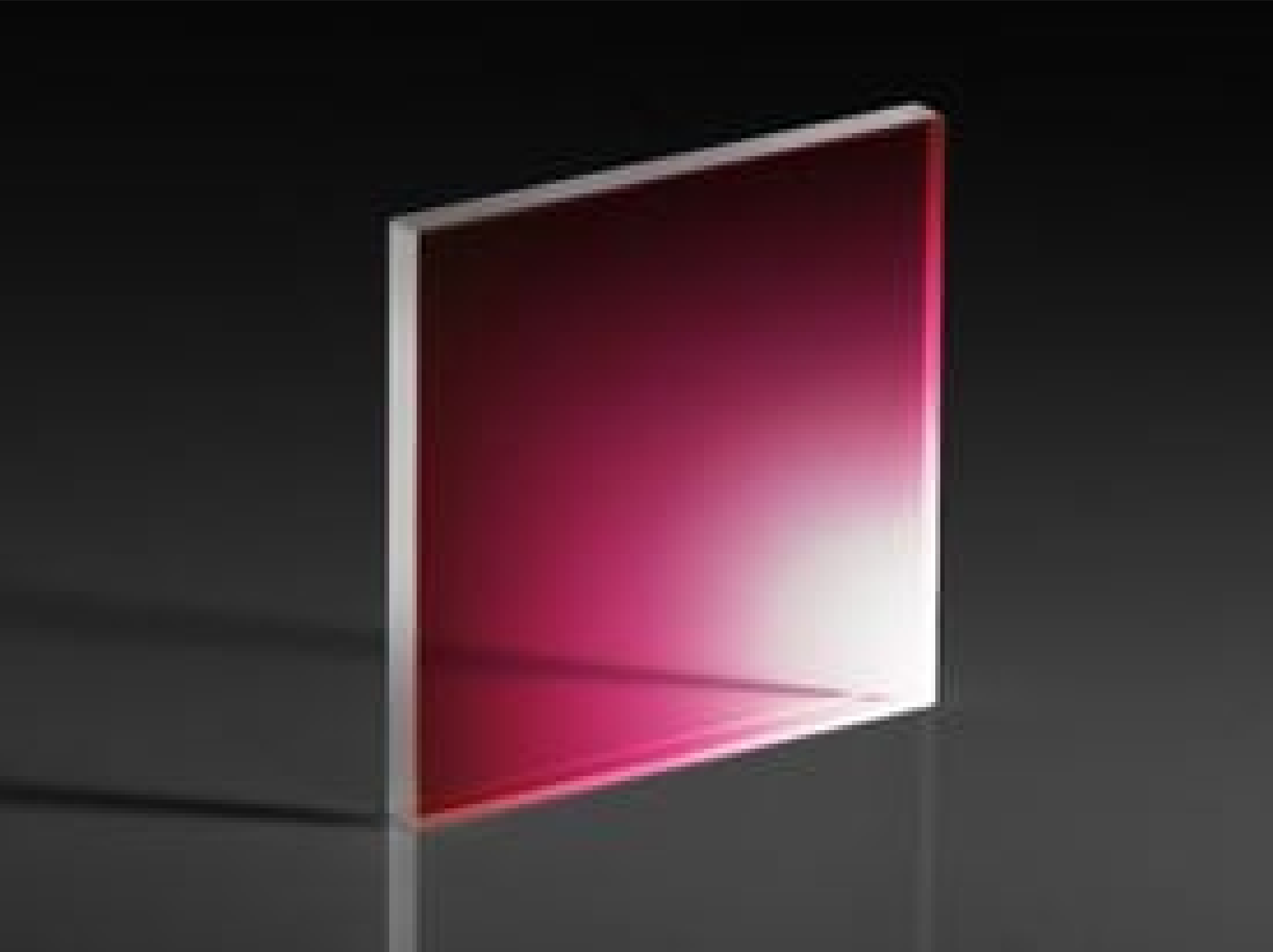

Stock #20-592 3-4 DAYS



1



€87,00

ADD TO CART

Qty 1-5

€87,00

Qty 6+

€69,50

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Abbe Number (v_d):
64.17

Bevel:
Protective as needed

Clear Aperture (%):
90

Clear Aperture CA (mm): 45.00 x 45.00
Dimensions (mm): 50.00 x 50.00 +0.00/-0.25
Thickness (mm): 1.00 ±0.20
Coating: Uncoated
Coefficient of Thermal Expansion CTE (10⁻⁶/°C): 7.1 (-30 to +70°C) 8.3 (+20 to +300°C)
Density (g/cm³): 2.51
Edges: Fine Ground
Index of Refraction n_d: 1.516
Knoop Hardness (kg/mm²): 610
Parallelism (arcmin): <1
Poisson's Ratio: 0.206
Substrate: N-BK7
Surface Quality: 60-40
Transmitted Wavefront, P-V: λ/4 (per 25mm Dia.)
Type: Protective Window
Wavelength Range (nm): 350 - 2200
Young's Modulus (GPa): 82
Length (mm): 50.00
Width (mm): 50.00

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View