


51.5mm Diameter Float Glass Window

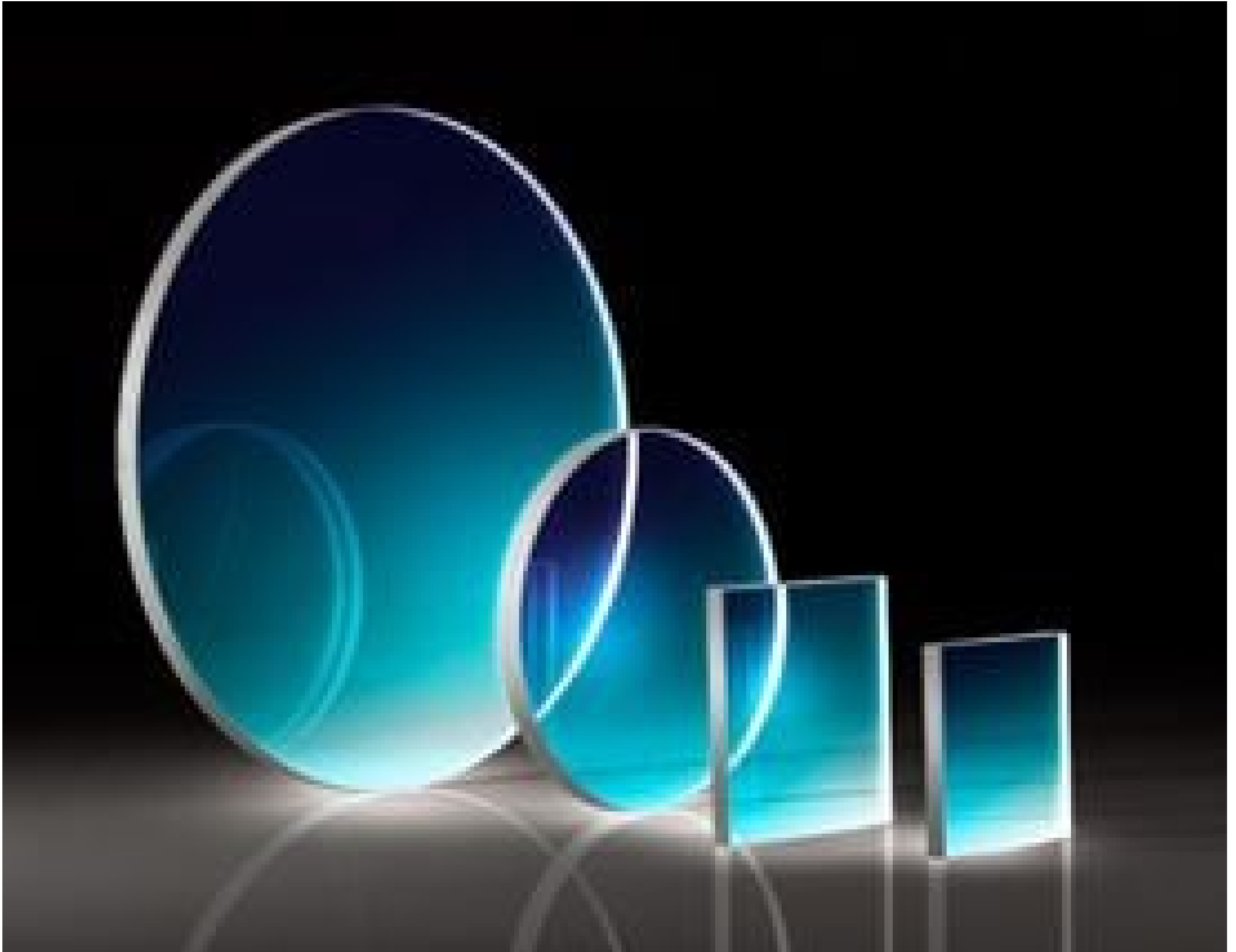

Stock #44-063 **20+ In Stock**

⊖ 1 ⊕ €18⁵⁰

ADD TO CART

Volume Pricing	
Qty 1-5	€18,50 each
Qty 6-49	€17,00 each
Qty 50-99	€15,00 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Protective Window **Type:**
Glass **Type of Window:**

Physical & Mechanical Properties

51.50 **Diameter (mm):**

1.50	Thickness (mm):
Protective as needed	Bevel:
Fine Ground	Edges:

Optical Properties

Uncoated	Coating:
Float Glass	Substrate: <input type="checkbox"/>
80-50	Surface Quality:
350 - 2000	Wavelength Range (nm):
4 - 6λ	Surface Flatness (P-V):

Regulatory Compliance

Compliant	RoHS 2015:
View	Certificate of Conformance:
Compliant	Reach 247:

Product Details

- Transmits Visible and Near Infrared Wavelengths
- Available Uncoated or with an Anti-Reflection Coating
- Variety of Sizes Available

Float Glass Optical Windows are optical glass with polished faces that are relatively parallel and are typically used as a protective element between two environments. Float glass readily transmits visible and near-infrared wavelengths and can be used in a wide variety of applications. Float Glass Optical Windows are versatile products offered in circular and rectangular options. They are available uncoated or with BBAR (Broadband Anti-Reflective) 400-700nm coating.

Compatible Mounts

;