


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

532nm, 15 X 15mm, Round Output, High Homogeneity Diffractive Diffuser

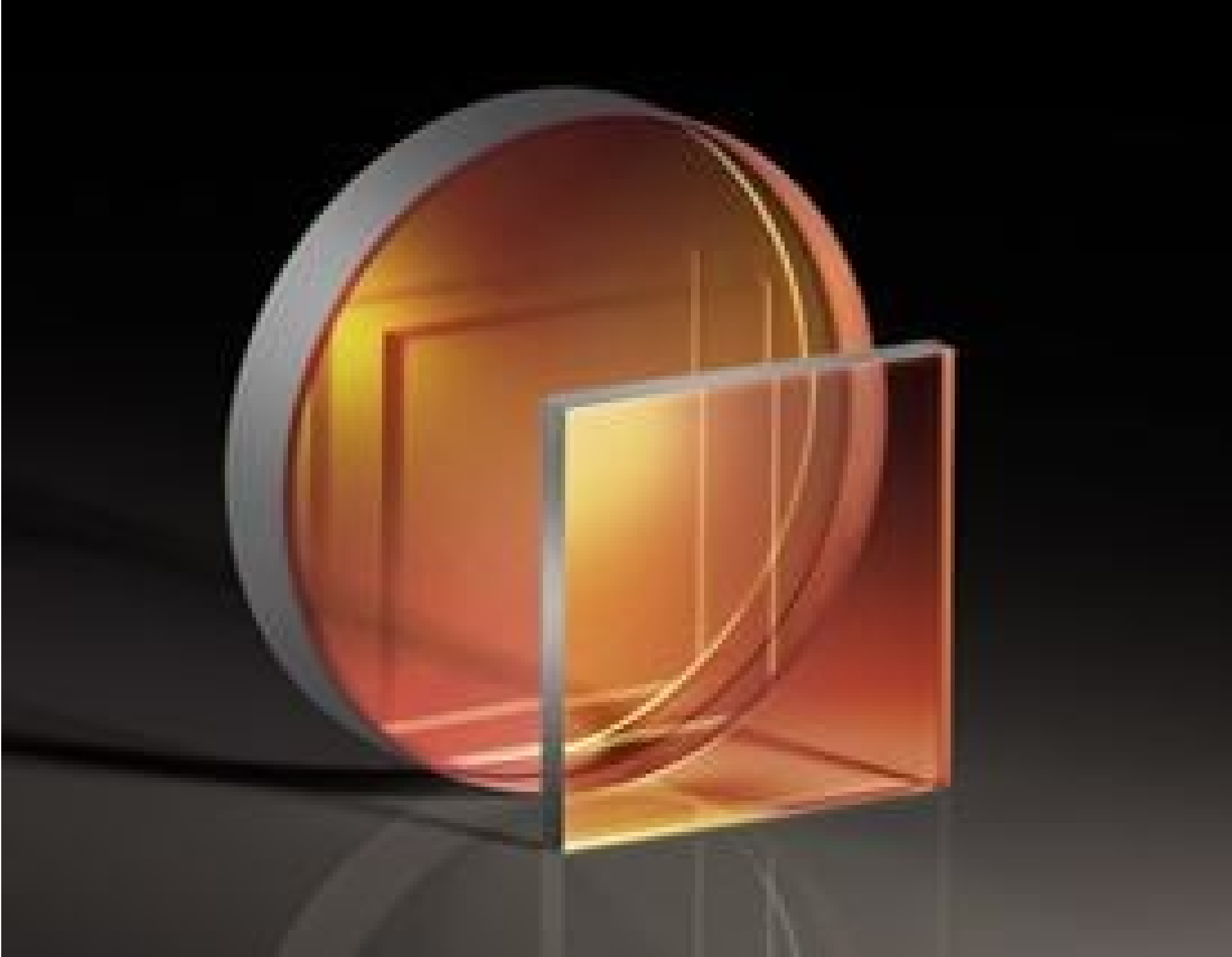

HOLO/OR Diffractive Diffusers

Stock #14-683 3-4 DAYS



1



€2.130,00

ADD TO CART

Qty 1+

€2.130,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Clear Aperture CA (mm):
13.50 x 13.50

Coating:
Laser V-Coat (532nm)

Design Wavelength DWL (nm):
532

Substrate:
[Fused Silica](#) (Corning 7980)

Length (mm): 15.00
Dimensions (mm): 15.00 x 15.00
Thickness (mm): 1.50 ±0.1
Width (mm): 15.00
Note: High Homogeneity
Input Beam Mode: SM or MM
Minimum Beam Diameter (mm): 1
Output Shape: Round
Overall Efficiency (%): 76
Full Angle (°) : 5.94
Damage Threshold, Reference:  See Link for More Details

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant