


TECHSPEC® 5mm VIS 0° Coated, BBAR Coated Right Angle Prism

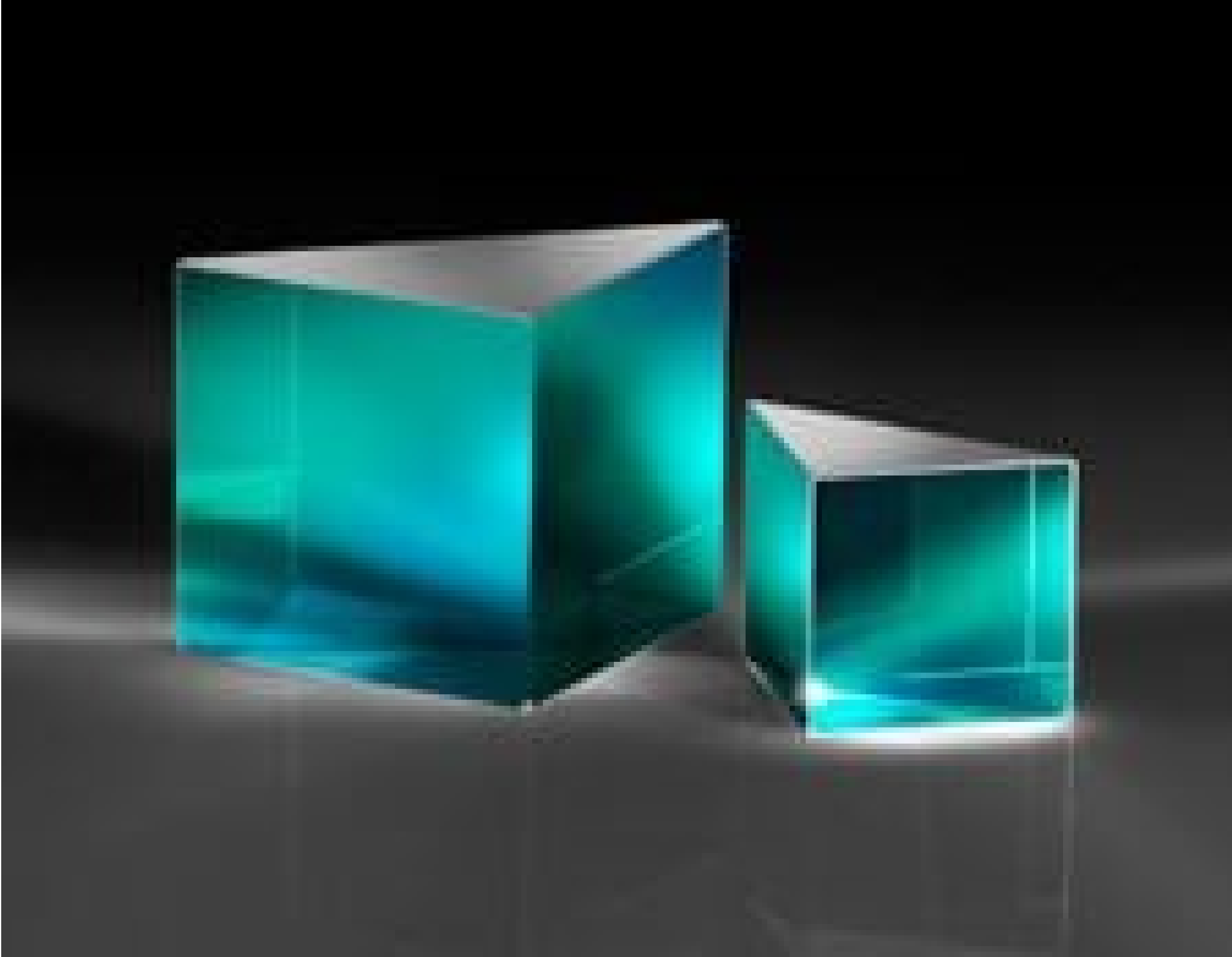

Stock **#84-505** 3-4 DAYS

- 1 + **€106,00**

ADD TO CART

Qty 1-5
€106,00

Qty 6+
€85,00

Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Angle Tolerance (arcsec):
±15

Coating:
VIS 0° (425-675nm)

Substrate: ☐
N-BK7

Surface Quality: 40-20
Type: Right Angle Prism
Dimensional Tolerance (mm): +0.00/-0.10
Bevel: Protective bevel as needed
Clear Aperture (%) : 90
Length of Hypotenuse (mm): 7.10
Length of Legs (mm): 5.00
Image Orientation: Left-Handed
Note: Coating on Entrance/Exit Faces
Coating Specification: R _{avg} ≤0.4% @ 425 - 675nm
Ray Deviation (°): 90
Wavelength Range (nm): 425 - 675
Surface Flatness (P-V): λ/8
Damage Threshold, Reference: ☐ Entrance/Exit Faces: 5 J/cm ² @ 532nm, 10ns

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View