


# 5mW, 635nm Laser Bat Power ZAT, 60° X-Hair

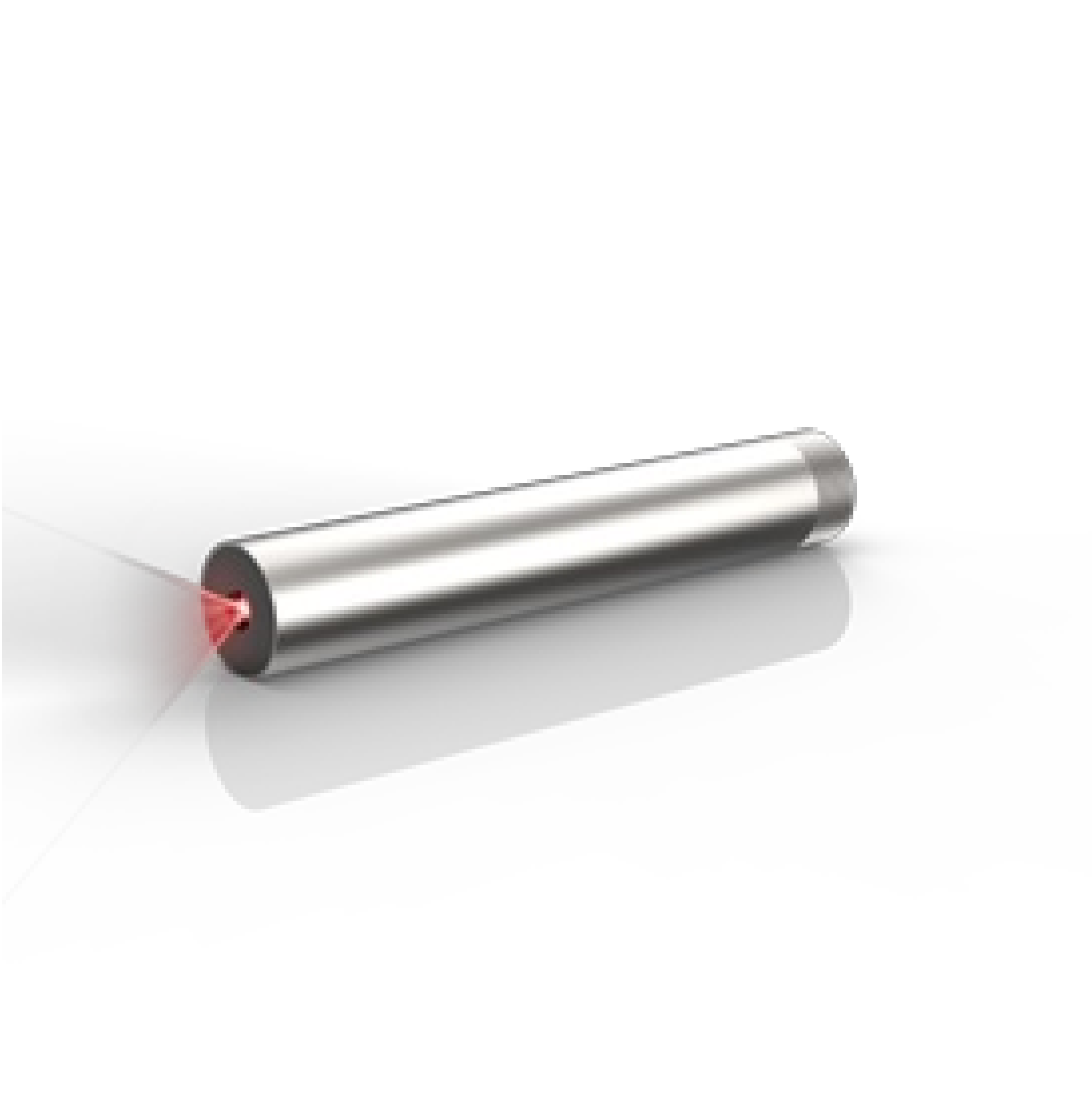

Stock **#19-540** [CONTACT US](#)



1



€255,00

ADD TO CART

|                |
|----------------|
| Qty 1-9        |
| €255,00        |
| Qty 10+        |
| €229,50        |
| Volume Pricing |

Get Product Downloads



**Output Power (mW):**  
5

**Wavelength (nm):**  
635.00

**Weight (g):**  
162

**Power Requirement:**  
1 AA Battery (Not Included)

**Style:**  
Crosshair

**Output Type:**  
Free Space

**Laser Class - CDRH:**  
1M

**Color:**  
Red

**Fan Angle (°):**  
60.00

**Focus Range:**  
Up to 1,500mm

**Length (mm):**  
124.00

**Environmental Rating:**  
IP40

Regulatory Compliance

**RoHS:**  
[Compliant](#)

**Certificate of Conformance:**  
[View](#)