


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

600 Grooves, 25mm Square, 1250nm NIR Ruled Grating

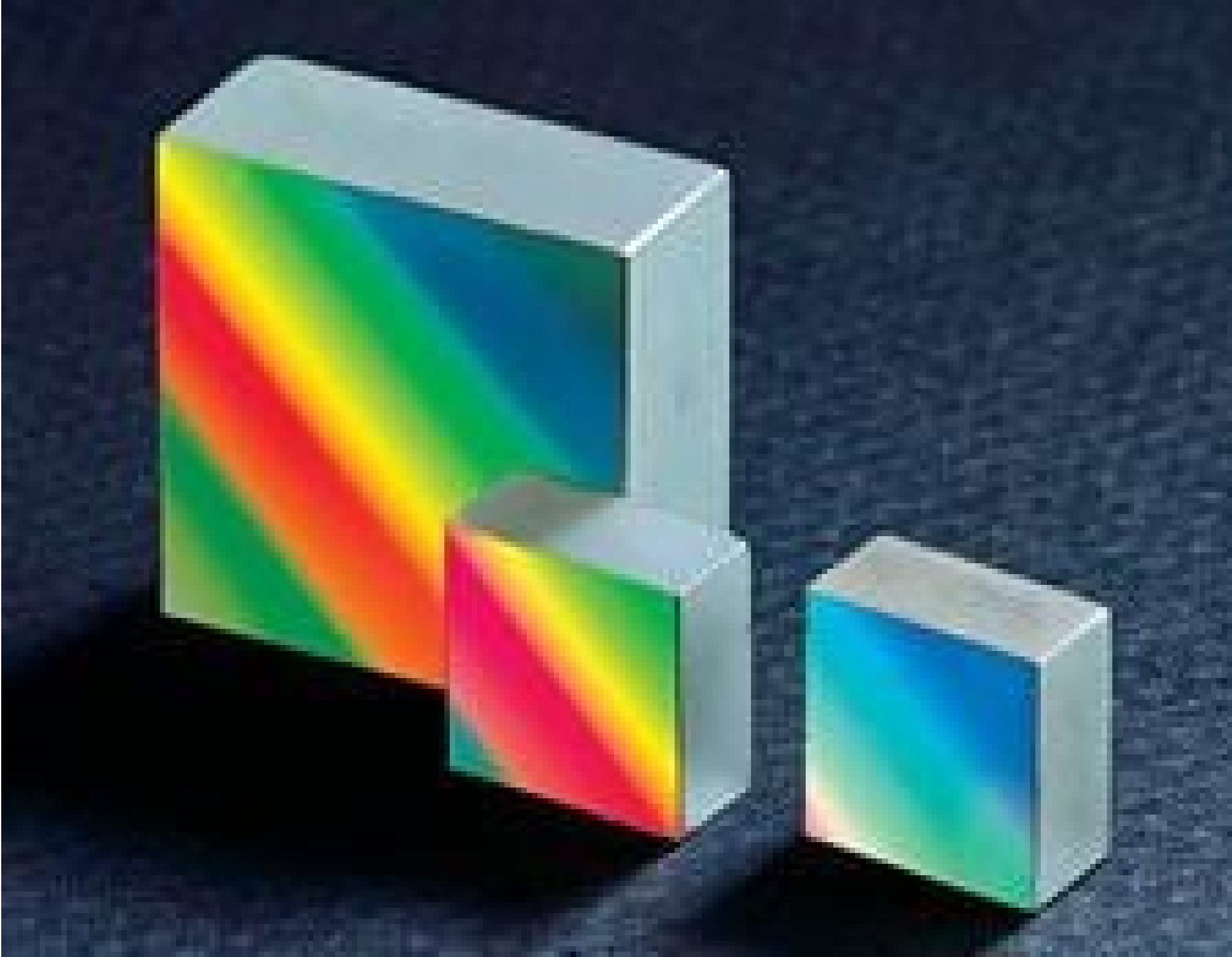

Stock #49-574 3-4 DAYS



1



€160,00

ADD TO CART

Qty 1+

€160,00

Volume Pricing

[Request Quote](#)

 Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Groove Density (grooves/mm):
600

Wavelength Range (nm):
700 - 3000

Blaze Wavelength (nm):
1250

Blaze Angle (°):
22.02

Dimensions (mm): 25.0 x 25.0 ±0.5
Clear Aperture (%): 90
Coating: Bare Gold
Construction: Ruled Grating
Direction of Grooves: Parallel to Short Dimension
Length (mm): 25.00
Substrate: ☐ Float Glass
Thickness (mm): 9.50 ±0.5
Type: Reflective Diffraction Grating
Width (mm): 25.00
Alignment of Grooves to Edge (°): ±0.5

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View