

6.5mm Travel, 0.002mm Grad. Mic. Drive S-Face



Drive Mechanisms

Stock #33-738 **1 In Stock**

− 1 + €176.⁰⁰

ADD TO CART

Volume Pricing

Qty 1-9	€176,00 each
Qty 10-24	€158,40 each
Need More?	Request Quote

! Prices shown are exclusive of VAT/local taxes

Product Downloads

SPECIFICATIONS

General

Metric
Type:
Manufacturer:

Physical & Mechanical Properties

6.5 **Travel (mm):**

0.002 **Graduation (mm):**

9.5 **Stem Diameter (mm):**

Plain/Spherical **Stem/Spindle:**

9.5 **Stem Length (mm):**

5 **Spindle Diameter (mm):**

14 **Min. Spindle Length (mm):**

13 **Max. Diameter (mm):**

55 **Overall Length (mm):**

Hardware & Interface Connectivity

Metric Micrometer **Type of Drive:**

Regulatory Compliance

[Exempt](#) **RoHS 2015:**

[View](#) **Certificate of Conformance:**

[Contains SVHC\(s\)](#) **REACH 241:**


PRODUCT DETAILS

- Micrometer, Fine Screw, Digital and Differential Options Available
- Compatible with our [Ball Bearing Stages](#)

These drive mechanisms add versatility to our selection of [ball bearing stages](#). Four options are available: micrometer (English and Metric), fine screw, digital, and differential.

Please reference individual product descriptions to see which stages are compatible with each drive mechanism.

TECHNICAL INFORMATION

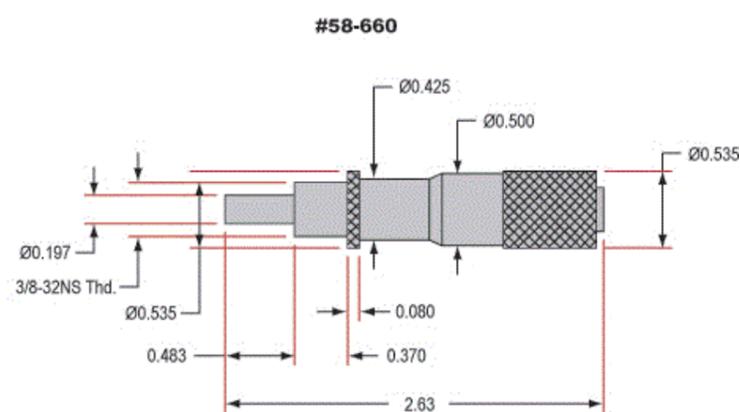

Units: inches