

[All Products](#) / [Optomechanics](#) / [Bench Mounting Systems](#) / [Articulating Arm Mounting Systems](#)

[See all 9 Products in Family](#)

# 6" Two-Arm Package



- 1 +

€120<sup>00</sup>

**ADD TO CART**

Select Your Country/Region: European Union

Submit

Volume Pricing	
Qty 1-9	€120,00 each
Qty 10+	€106,30 each
Need More?	<a href="#">Request Quote</a>

Product Downloads
<a href="#">EO Spec Sheet</a>

Prices shown are exclusive of VAT/local taxes

## General

<b>Type:</b> English	<b>Note:</b> 6" Two-Arm Package
<b>Knuckles:</b> 4	<b>Shafts:</b> (2) 6"

## Physical & Mechanical Properties

<b>Coarse Rotation (°):</b> 360	<b>Construction:</b> 6061-T6 Aluminum, Black Anodized Finish Shaft 6061-T6 Aluminum Natural Finish Pivot Ball Zinc Die Cast, Natural Finish Locking Ring
---------------------------------	--

## Regulatory Compliance

<b>RoHS 2015:</b> <a href="#">Compliant</a>	<b>Certificate of Conformance:</b> <a href="#">View</a>
---	---

## Product Details


- Mount and Set in Unique Orientations
- Mix and Match for Custom Mounting Combinations
- Lockable Angular Positioning

Articulating Arm Mounting Systems are designed to reach into areas not easily accessible with standard ¼-20 mounting. These "arms" can be positioned in any angular setting (180°) via the ball-pivot assembly. A total 360° rotation can be achieved by tilting/turning the knuckle about the shaft. The position can be locked with the easily handled knob or the tamper-resistant set screw (Allen Key included). Articulating Arm Mounting Systems can be used for applications ranging from mounting optical assemblies to fixturing cameras. Individual components are available, as well as One-Arm and Two-Arm packages. The One-Arm package includes two knuckles and one shaft, and the Extended One-arm package includes three knuckles and two shafts for added reach and range. Our Two-Arm package includes four knuckles and two shafts for separate arm requirements, such as alignment of dual branch fiber optic light guides. Nylon washers are provided with knuckles to avoid scratching anodized surfaces. Additional [optical bench hardware set screws](#) (not included) are available.

# Technical Information

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

Select Your Country/Region:

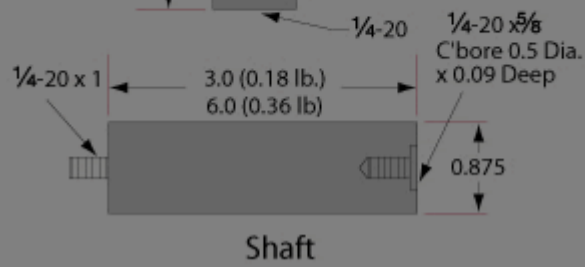

Units: Inches

## Related Products



English and Metric Magnetic Bases



Low Profile Magnetic Bases



Threaded Base Plates



Slotted 2" x 3" Base Plates

## Frequently Purchased Together



#03-640 - 24" x 12", Breadboard  
€387,00

Qty



#03-631 - 0.5mm Thick, C-Mount Brass Spacer Ring  
€11,25

Qty



#03-632 - 1.0mm Thick, C-Mount Brass Spacer Ring  
€11,25

Qty



#03-633 - 2.0mm Thick, C-Mount Brass Spacer Ring  
€11,25

Qty



# Resources

### Media Type

- FAQ
- Glossary
- Application Note

? FAQ

Do you have any components that would...

? FAQ

Do your iris diaphragms have mounts for...

GLOSSARY

Axial Runout

Trending in Optics

Video

Please select your shipping country to view the most accurate inventory information, and to determine the correct Edmund Optics sales office for your order.

**Select Your Country/Region:**

GLOSSARY

Tangent Arm Drive

[View More](#)